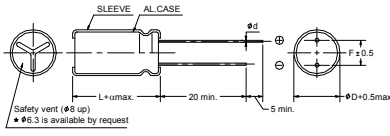


ALUMINIUM ELECTROLYTIC CAPACITORS SPECIFICATION FOR APPROVAL 铝电解电容规格承认书			
CUSTOMER 客户		MANUFACT 供货方	
USED SPEC 通用规格	470uf/50V	KD SCODE 品名	铝电解电容
TYPE'S DIMENSIONS(MM) 形状及尺寸 		D:	10
		L:	20
		F:	5.0
SPECIFICATIONS 规格			
OPERATING TEMPERATURE RANGE 使用温度		-40~105℃	
RATED VOLTAGE 额定电压		50V	
NOMINAL CAPACITANCE 标称容量		470uf	
CAPACITY TOLERANCE 电容量允许偏差		±20%	
LEAKAGE CURRENT 漏电流		小于 235uA (加额定电压两分钟后读数)	
TANGENT OF LOSS ANGLE (20±5℃ 120Hz) 损耗角正切		<0.10	
ENDURANCE (105℃ 1000h) 耐久性		1. I< 初始规定值 2. ΔC/C<30% 3. tga<150 初始规定值	
OTHERS 其他			
CUSTOMER'S SIGNATURE 贵公司承认栏			