


产品详细信息 introduce

线对板连接器 >> Du Pont1.27

产品订购

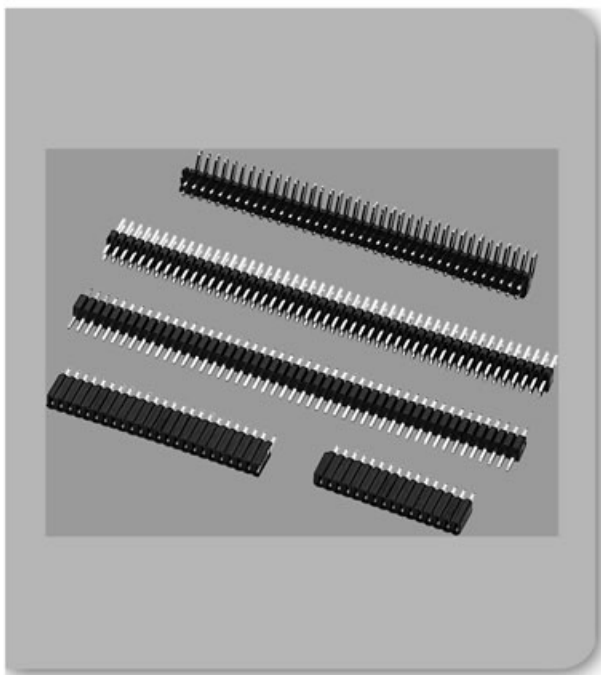



**SPECIFICATIONS**

 Unit:mm



- ◇ Poles: 2~40
- ◇ Applicable wire: AWG#26-#30
- ◇ Voltage rating: 250V DC/AC
- ◇ Current rating: 1.0A
- ◇ Withstand voltage: 800V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.01Ω
- ◇ Applicable PC board thickness: 0.6~1.2mm

UL:Recognized No.E309635  
 RoHS-specification and  
 Halogen-free products

**Du Pont1.27-1-nA**

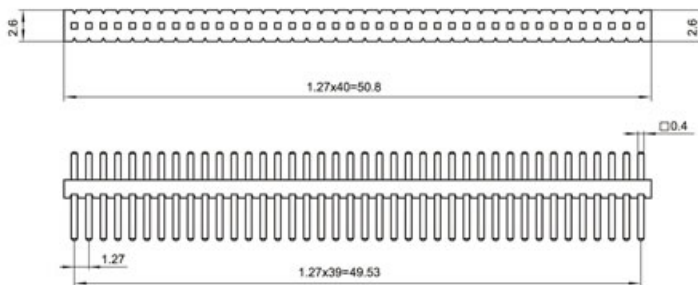




**Du Pont1.27-2-nA**

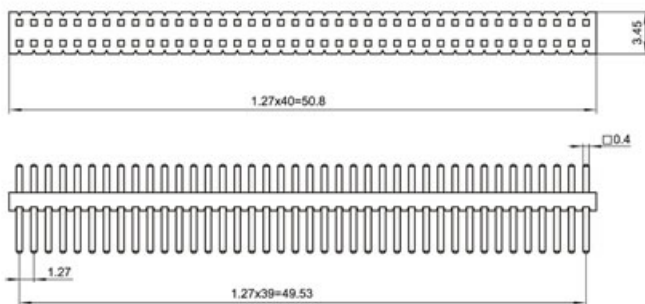 


**Du Pont1.27-2-nAW**

 Unit:mm

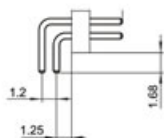

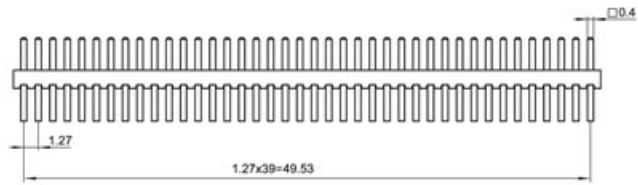

**Du Pont1.27 排母**

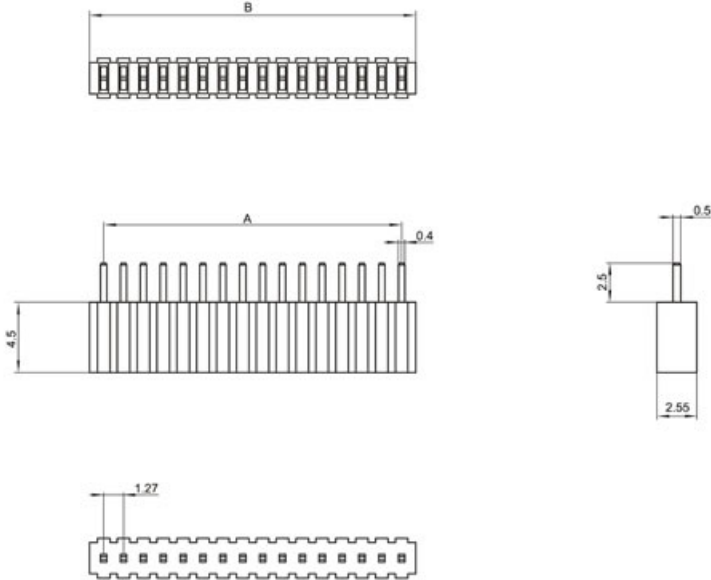

| Poles | Type            | Size(mm) |       |
|-------|-----------------|----------|-------|
|       |                 | A        | B     |
| 2     | Du Pont1.27-2A  | 1.27     | 3.07  |
| 3     | Du Pont1.27-3A  | 2.54     | 4.34  |
| 4     | Du Pont1.27-4A  | 3.81     | 5.61  |
| 5     | Du Pont1.27-5A  | 5.08     | 6.88  |
| 6     | Du Pont1.27-6A  | 6.35     | 8.15  |
| 7     | Du Pont1.27-7A  | 7.62     | 9.42  |
| 8     | Du Pont1.27-8A  | 8.89     | 10.69 |
| 9     | Du Pont1.27-9A  | 10.16    | 11.96 |
| 10    | Du Pont1.27-10A | 11.43    | 13.23 |
| 11    | Du Pont1.27-11A | 12.7     | 14.5  |
| 12    | Du Pont1.27-12A | 13.97    | 15.77 |
| 13    | Du Pont1.27-13A | 15.24    | 17.04 |
| 14    | Du Pont1.27-14A | 16.51    | 18.31 |
| 15    | Du Pont1.27-15A | 17.78    | 19.58 |
| 16    | Du Pont1.27-16A | 19.05    | 20.85 |
| 17    | Du Pont1.27-17A | 20.32    | 22.12 |
| 18    | Du Pont1.27-18A | 21.59    | 23.39 |
| 19    | Du Pont1.27-19A | 22.86    | 24.66 |
| 20    | Du Pont1.27-20A | 24.13    | 25.93 |

点击次数: 1640 发布时间: 2010-6-14 【打印】 【返回】

产品订购