


产品详细信息 introduce

线对板连接器 >> Du Pont2.54

产品订购

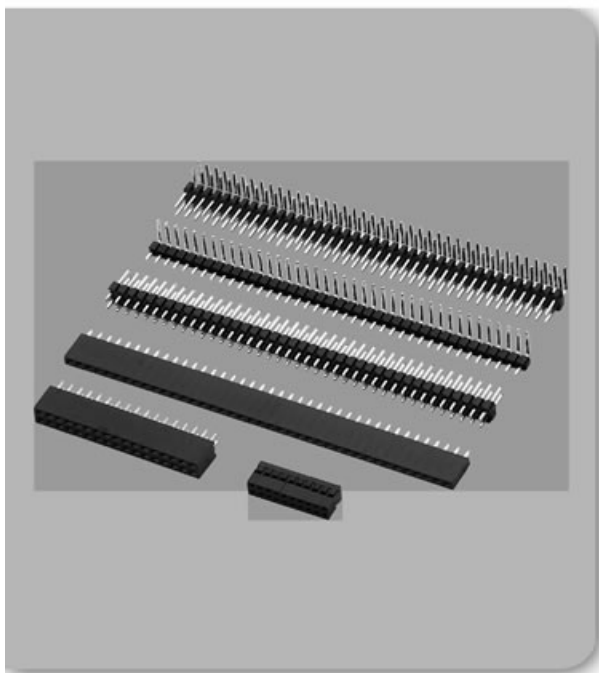


◆ SPECIFICATIONS

Unit:mm


- ◇ Poles: (YS)~35x2、(AS、WAS)2~40x2
- ◇ Applicable wire: AWG#22-#28
- ◇ Voltage rating: 250V DC/AC
- ◇ Current rating: 3.0A
- ◇ Withstand voltage: 800V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.02Ω

UL:Recognized No.E309635  
 RoHS-specification and  
 Halogen-free products


Du Pont2.54 双排母

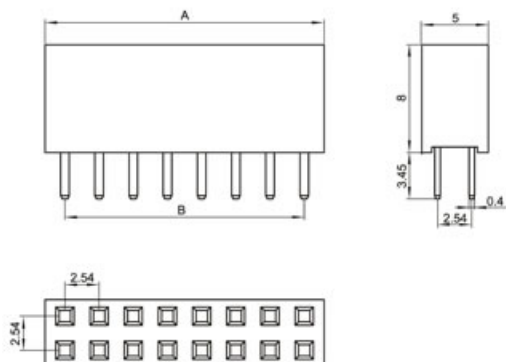


Du Pont2.54 单排母

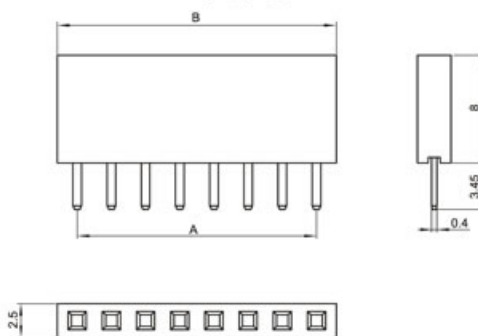


Du Pont2.54-nYS

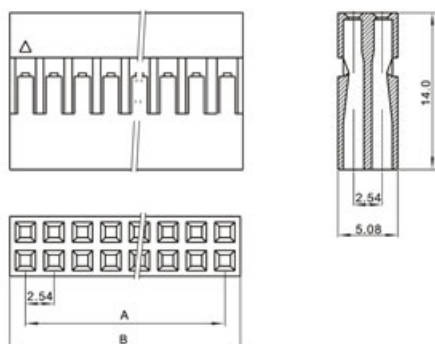


Du Pont2.54-nA

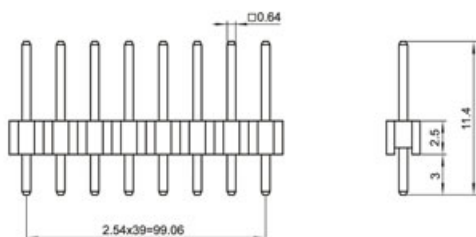



Du Pont2.54-2xnA

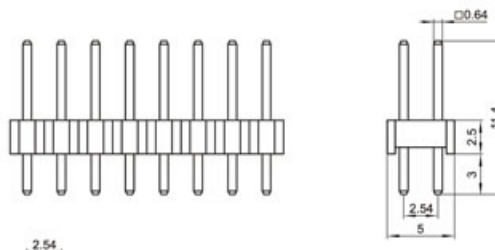




Unit:mm

 




**Du Pont2.54-nAW**

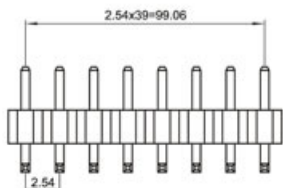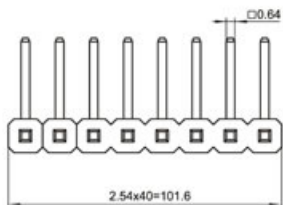

**Du Pont2.54-PT**

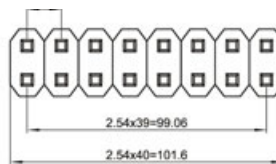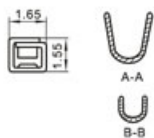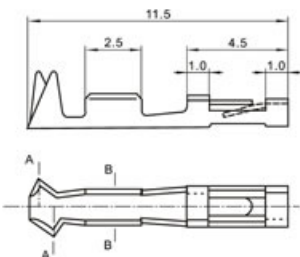

**Du Pont2.54-2xnAW**

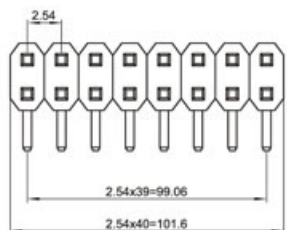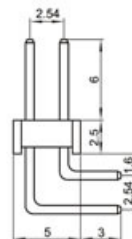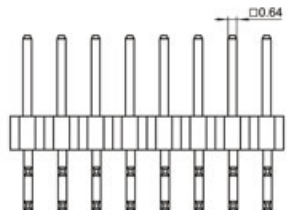

**Terminal(Du Pont2.54)**

| Type           | Applicable wires |       | O.D of wire ins<br>mm | Material    | Finish     |
|----------------|------------------|-------|-----------------------|-------------|------------|
|                | mm <sup>2</sup>  | AWG#  |                       |             |            |
| BM-Du Pont2.54 | 0.08-0.3         | 22-28 | 1.0-1.7               | Phos.bronze | Tin-plated |

| Poles | Type               | Size(mm) |       |
|-------|--------------------|----------|-------|
|       |                    | A        | B     |
| 4     | Du Pont2.54-2x2YS  | 2.54     | 5.34  |
| 6     | Du Pont2.54-2x3YS  | 5.08     | 7.88  |
| 8     | Du Pont2.54-2x4YS  | 7.62     | 10.42 |
| 10    | Du Pont2.54-2x5YS  | 10.16    | 12.96 |
| 12    | Du Pont2.54-2x6YS  | 12.70    | 15.50 |
| 14    | Du Pont2.54-2x7YS  | 15.24    | 18.04 |
| 16    | Du Pont2.54-2x8YS  | 17.78    | 20.58 |
| 18    | Du Pont2.54-2x9YS  | 20.32    | 23.12 |
| 20    | Du Pont2.54-2x10YS | 22.86    | 25.66 |
| 22    | Du Pont2.54-2x11YS | 25.40    | 28.20 |
| 24    | Du Pont2.54-2x12YS | 27.94    | 30.74 |

| Poles | Type              | Size(mm) |       |
|-------|-------------------|----------|-------|
|       |                   | A        | B     |
| 26    | Du Pont2.54-2x13Y | 30.48    | 33.28 |
| 28    | Du Pont2.54-2x14Y | 33.02    | 35.82 |
| 30    | Du Pont2.54-2x15Y | 35.56    | 38.36 |
| 32    | Du Pont2.54-2x16Y | 38.10    | 40.90 |
| 34    | Du Pont2.54-2x17Y | 40.64    | 43.44 |
| 36    | Du Pont2.54-2x18Y | 43.18    | 45.98 |
| 38    | Du Pont2.54-2x19Y | 45.72    | 48.52 |
| 40    | Du Pont2.54-2x20Y | 48.26    | 51.06 |
| ...   | ...               | ...      | ...   |
| 70    | Du Pont2.54-2x35Y | 86.36    | 89.16 |

点击次数: 1240 发布时间: 2010-6-14 【打印】 【返回】

