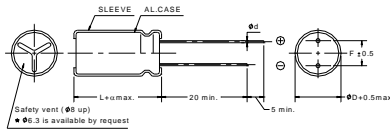


ALUMINIUM ELECTROLYTIC CAPACITORS SPECIFICATION FOR APPROVAL 铝电解电容规格承认书			
<b>CUSTOMER</b> 客户		<b>MANUFACT</b> 供货方	
<b>USED SPEC</b> 通用规格	<b>470uf/25V</b>	<b>KD SCODE</b> 品名	铝电解电容
<b>TYPE'S DIMENSIONS(MM)</b> 型状及尺寸 		<b>D:</b>	<b>8</b>
		<b>L:</b>	<b>12</b>
		<b>F:</b>	<b>3.5</b>
<b>SPECIFICATIONS</b> 规格			
<b>OPERATING TEMPERATURE RANGE</b> 使用温度		<b>-40~105℃</b>	
<b>RATED VOLTAGE</b> 额定电压		<b>25V</b>	
<b>NOMINAL CAPACITANCE</b> 标称容量		<b>470uf</b>	
<b>CAPACITY TOLERANCE</b> 电容量允许偏差		<b>±20%</b>	
<b>LEAKAGE CURRENT</b> 漏电流		<b>小于 117.5uA</b> (加额定电压两分钟后读数)	
<b>TANGENT OF LOSS ANGLE</b> (20±5℃ 120Hz) 损耗角正切		<b>&lt;0.14</b>	
<b>ENDURANCE</b> (105℃ 2000h) 耐久性		1. I<初始规定值 2. ΔC/C<30% 3. tga<150 初始规定值	
<b>OTHERS</b> 其他			
<b>CUSTOMER'S SIGNATURE</b> 贵公司承认栏			