

材质及电镀

间距: 3.5/3.81mm
极数: 2 × (2P-24P)
焊针: 黄铜、镀锡
塑件: PA66.UL94V-0

MATERIAL

Pitch: 3.5/3.81mm
Poles: 2 × (2P-24P)
Pin header: Brass、Tin plated
Housing: PA66. UL94V - 0

电气性能

额定电压: 300V
额定电流: 8A
耐电压: AC2000V/1Min

ELECTRICAL


Rated voltage: 300V
Rated current: 8A
Withstanding voltage: AC2000V/1M

机械性能

温度范围: -40℃~+105℃
瞬时温度: +250℃5秒

MECHANICAL

Temperature range: -40℃~+105℃
MAX soldering: + 250℃ for 5 sec.

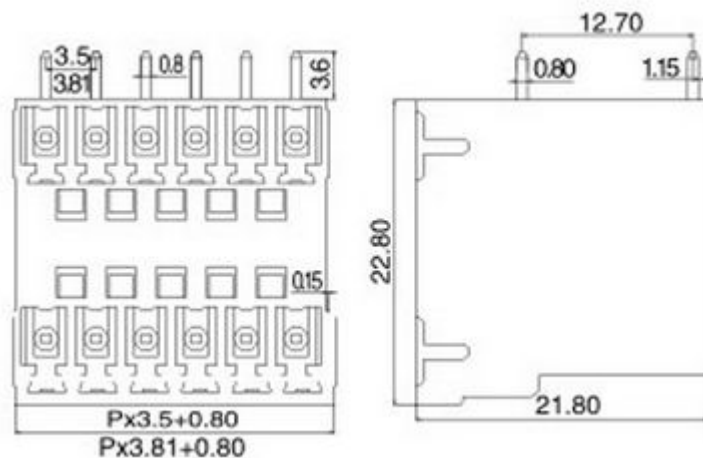

产品图片

