


间距：3.5/3.81mm；极数：2x (2P)

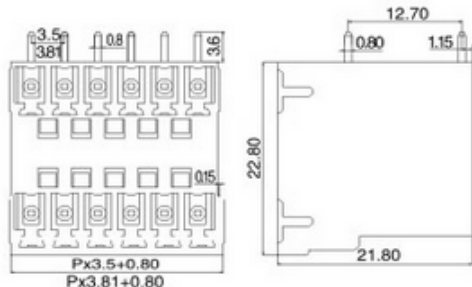

材质及电镀

间距：3.5/3.81mm
极数：2x (2P-24P)
焊针：黄铜、镀锡
塑件：PA66.UL94V-0

电气性能

额定电压：300V
额定电流：8A
耐电压：AC2000V/1Min

机械性能

温度范围：-40℃~+105℃
瞬时温度：+250℃5秒

MATERIAL

Pitch: 3.5/3.81mm
Poles: 2x (2P-24P)
Pin header: Brass, Tin plated
Housing: PA66. UL94V-0

ELECTRICAL

Rated voltage: 300V
Rated current: 8A
Withstanding voltage: AC2000V/1Min

MECHANICAL

Temperature range: -40℃~+105℃
MAX soldering: +250℃ for 5 sec.