


■ 技术参数 SPECIFICATION

- ◆ 间距: 3.0  
Pitch: 3.0
- ◆ 线数: 2~12  
Poles: 2~12
- ◆ 适用线规: AWG#20~28  
Applicable wire: AWG#20~28
- ◆ 额定电压: 250V DC/A  
Voltage rating: 250V D
- ◆ 额定电流: 5.0A  
Current rating: 5.0A
- ◆ 耐压值: 1500V AC(有)  
Withstand voltage: 1500V AC
- ◆ 工作温度: -40℃~+105℃  
Working Temperature: -40℃~+105℃
- ◆ 绝缘电阻:  $\geq 1000M\Omega$   
Insulation resistance:  $\geq 1000M\Omega$
- ◆ 接触电阻:  $\leq 10m\Omega$   
Contact resistance:  $\leq 10m\Omega$

外壳 <Y>  
HOUSING

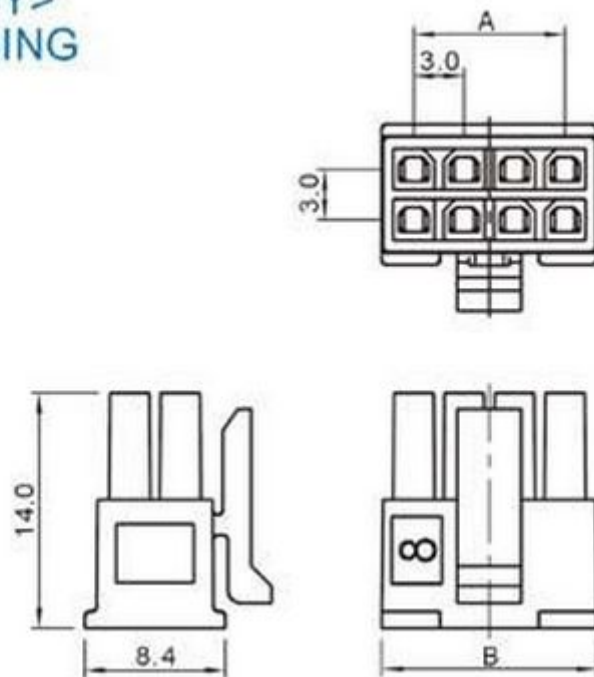

线数 Poles	尺寸 Dimens	
	A	B
2×1	N/A	3.85
2×2	3.0	6.85
2×3	6.0	9.85
2×4	9.0	12.85
2×5	12.0	15.85
2×6	15.0	18.85
2×7	18.0	21.85
2×8	21.0	24.85
2×9	24.0	27.85
2×10	27.0	30.85
2×11	30.0	33.85
2×12	33.0	36.85

## 产品图片

