


◆ SPECIFICATIONS

Unit:mm

- ◇ Poles: 2~24
- ◇ Applicable wire: AWG#28-#20
- ◇ Voltage rating: 300V DC/AC
- ◇ Current rating: 9A
- ◇ Withstand voltage: 1500V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance:  $\geq 1000M\Omega$
- ◇ Contact resistance:  $\leq 0.015\Omega$
- ◇ Applicable PC board thickness: 1.6mm

5559-nP

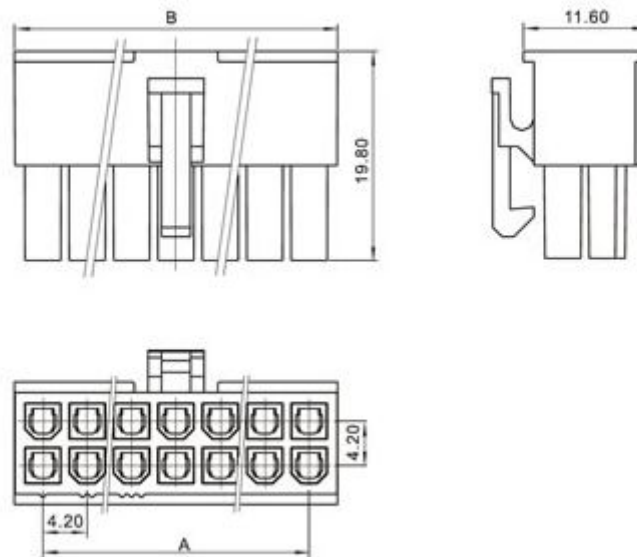

Poles	Type	Size(mm)	
		A	B
2x1	5559-2P	0	5.60
2x2	5559-4P	4.20	9.80
2x3	5559-6P	8.40	14.00
2x4	5559-8P	12.60	18.20
2x5	5559-10P	16.80	22.40
2x6	5559-12P	21.00	26.60
2x7	5559-14P	25.20	30.80
2x8	5559-16P	29.40	35.00
2x9	5559-18P	33.60	39.20
2x10	5559-20P	37.80	43.40
2x11	5559-22P	42.00	47.60
2x12	5559-24P	46.20	51.80

## 产品图片

