


此商品对应的规格参数

插座.蓝色 5566-2A 针/5566-2A 空心针 2*1


此商品实物图

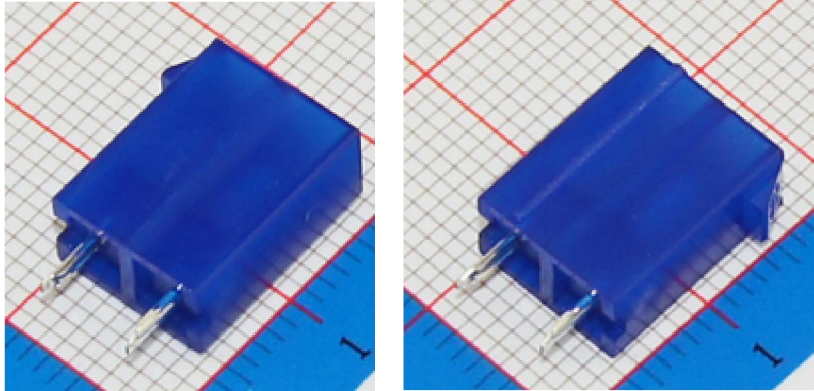


规格参数 (mm)

- 技术参数 SPECIFICATIONS**
- 线数 (Poles) : 2~24
 - 适用线规 (Applicable wires) : AWG32#~20#
 - 适应基板厚度 (Applicable PC board thickness) : 1.6mm
 - 温度范围 (Temperature range) : -25℃~85℃
 - 额定电压 (Voltage rating) : 300V.Ac/Dc
 - 额定电流 (Current rating) : 9A max
 - 接触电阻 (Contact resistance) : $\leq 0.015\Omega$
 - 绝缘电阻 (Insulation resistance) : $\geq 1000M\Omega$
 - 耐压 (Withstand voltage) : 1500V.Ac/1min
- 材料 (Material) :
- 孔座 (Housing) : 尼龙 (PA66) UL94V-2
 - 针座 (Wafer) : 尼龙 (PA66) UL94V-2
 - 端子 (Terminal) : 磷青铜 (Phos.bronze Tin/plated)

注: 下图中 A = 0, B = 5.4mm

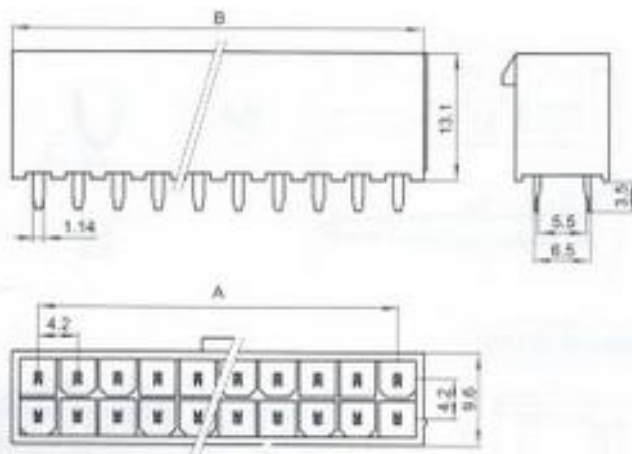

■ 安装尺寸 MOUNTING MEASUREMENT

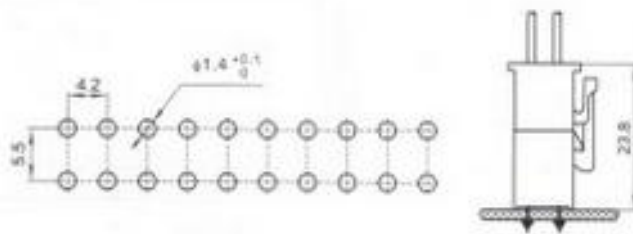

5566-A