


此商品对应的规格参数

EL 簧 母/端子

此商品实物图

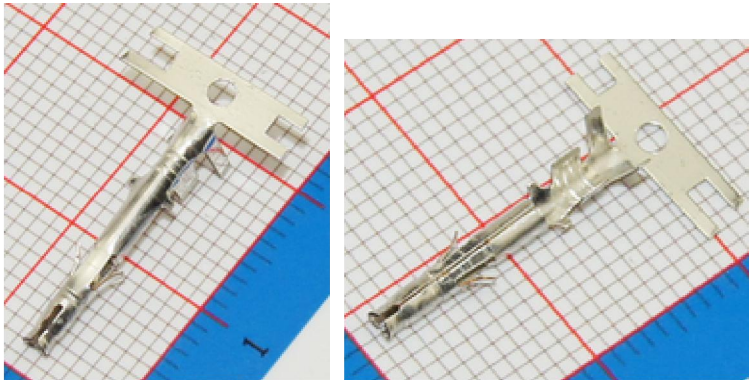

◆ SPECIFICATIONS

Unit:mm

- ◇ Poles: 2、3、4、6、9、12、15
- ◇ Applicable wire: AWG#26-#18
- ◇ Voltage rating: 300V DC/AC
- ◇ Current rating: 10~6A
- ◇ Withstand voltage: 1500V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: $\geq 1000M\Omega$
- ◇ Contact resistance: $\leq 0.015\Omega$
- ◇ Applicable PC board thickness: 1.6mm

