


产品详细信息 introduce

线对线连接器 >> 5557、5566、5569

产品订购

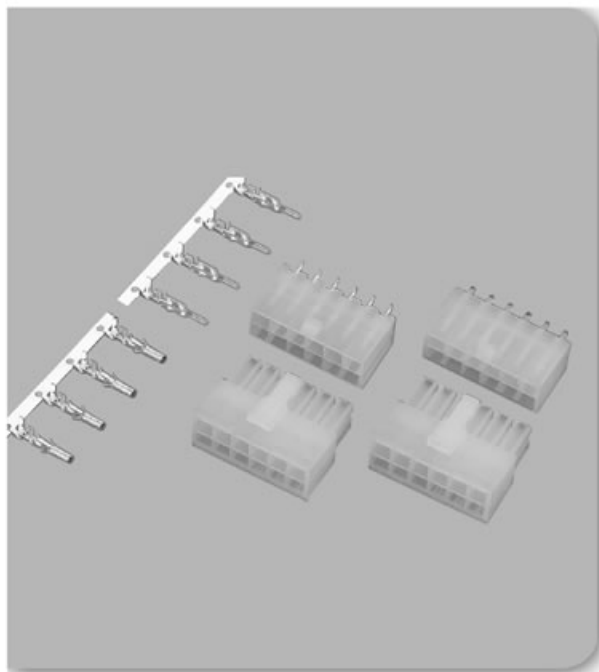

◆ SPECIFICATIONS

Unit:mm

- ◇ Poles: 2-6、8、10、12、14、16、18、20、22、24
- ◇ Applicable wire: AWG#28-#20
- ◇ Voltage rating: 300V DC/AC
- ◇ Current rating: 9A max
- ◇ Withstand voltage: 1500V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: ≥ 1000MΩ
- ◇ Contact resistance: ≤ 0.015Ω
- ◇ Applicable PC board thickness: 1.6mm

UL:Recognized No.E309635
RoHS-specification and Halogen-free products

◆ TERMINAL


Terminal is interchangeable with 5557 Terminal

◆ HOUSING



Housing is interchangeable with 5557 Receptacle housing

Mounting Measurement

5566-nA

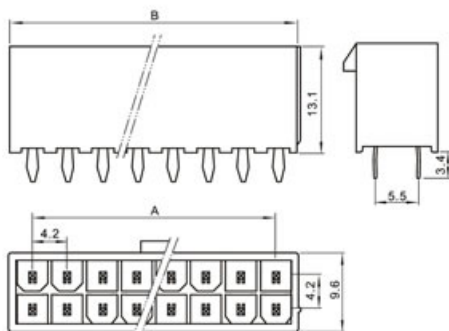

5569-nA

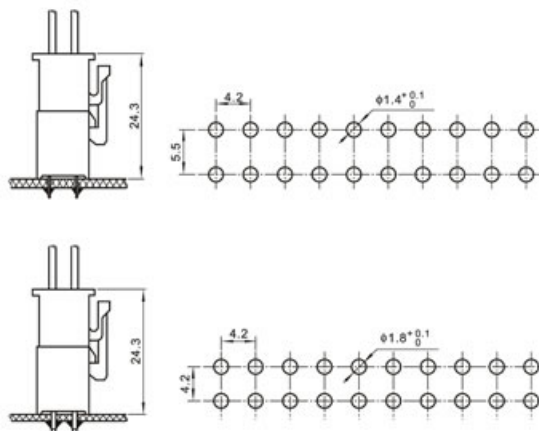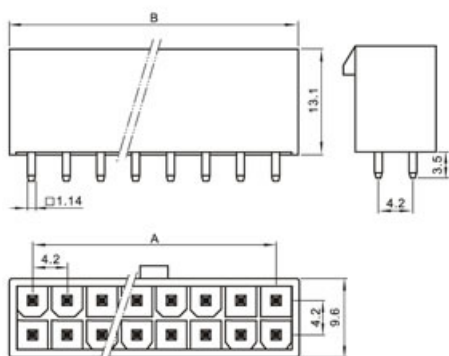

Poles	Type Vertical (90°)		Size(mm)	
			A	B
2	5566-2A	5569-2A	0	5.4
3	5566-3A	—	8.4	13.8
4	5566-4A	5569-4A	4.2	9.6
5	5566-5A	—	16.8	22.2
6	5566-6A	5569-6A	8.4	13.8
8	5566-8A	5569-8A	12.6	18.0
10	5566-10A	5569-10A	16.8	22.2
12	5566-12A	5569-12A	21.0	26.6
14	5566-14A	5569-14A	25.2	30.6
16	5566-16A	5569-16A	29.4	34.8
18	5566-18A	5569-18A	33.6	39.0
20	5566-20A	5569-20A	37.8	43.2
22	5566-22A	5569-22A	42.0	47.4
24	5566-24A	5569-24A	46.2	51.6

点击次数: 1910 发布时间: 2010-6-14 【打印】 【返回】

产品订购