


产品详细信息 introduce

线对线连接器 >> 5557、5559

产品订购

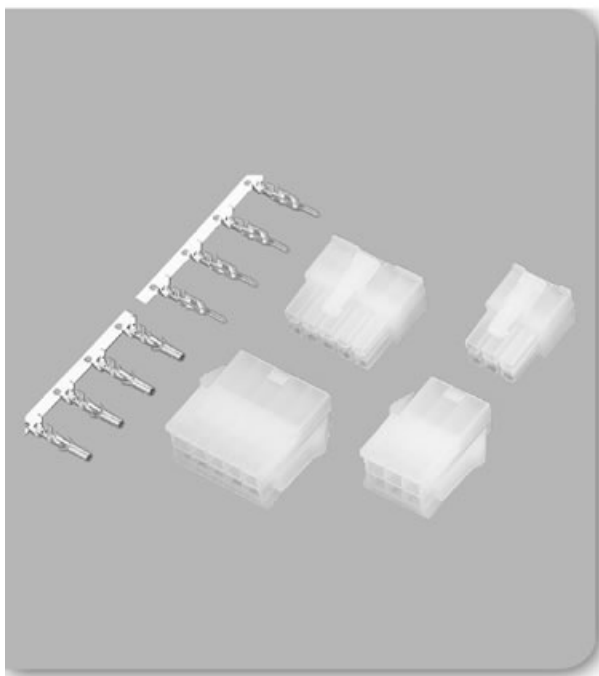


SPECIFICATIONS

Unit:mm


- ◇ Poles: 2~24
- ◇ Applicable wire: AWG#28-#20
- ◇ Voltage rating: 300V DC/AC
- ◇ Current rating: 9A
- ◇ Withstand voltage: 1500V AC
- ◇ Working Temperature: -25°C ~ +85°C
- ◇ Insulation resistance: $\geq 1000M\Omega$
- ◇ Contact resistance: $\leq 0.015\Omega$
- ◇ Applicable PC board thickness: 1.6mm

UL:Recognized No.E309635
 RoHS-specification and
 Halogen-free products


5559-nP

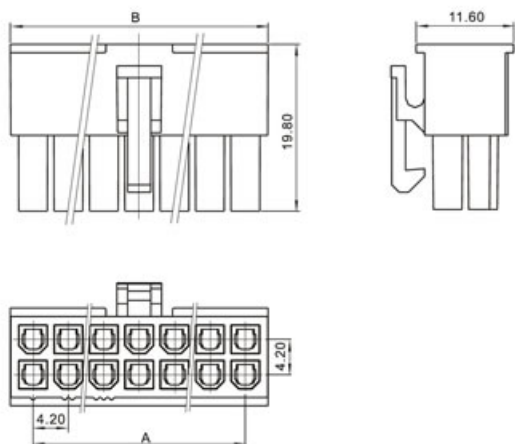

5559-nR

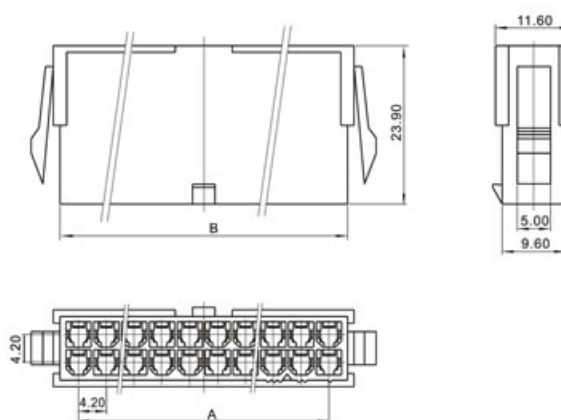


5559-PT

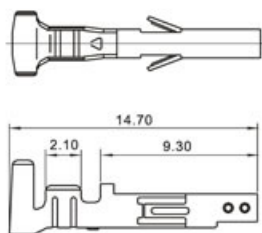



Mounting Measurement

Unit:mm

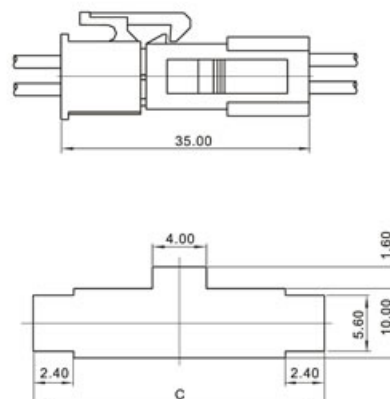

5559-RT

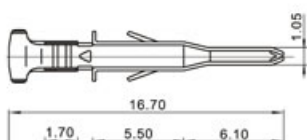

 

Terminal(5559)

Type	Applicable wires		O.D of wire ins	Material	Finish
	mm ²	AWG#	mm		
BM-5559	0.08-0.3	28-20	0.90-1.90mm	Phos.bronze	Tin-plated

Poles	Type	Size(mm)	
		A	B
2x1	5559-2P	0	5.60
2x2	5559-4P	4.20	9.80
2x3	5559-6P	8.40	14.00
2x4	5559-8P	12.60	18.20
2x5	5559-10P	16.80	22.40
2x6	5559-12P	21.00	26.60
2x7	5559-14P	25.20	30.80
2x8	5559-16P	29.40	35.00
2x9	5559-18P	33.60	39.20
2x10	5559-20P	37.80	43.40
2x11	5559-22P	42.00	47.60
2x12	5559-24P	46.20	51.80

Poles	Type	Size(mm)		
		A	B	C
2x1	5559-2R	0	5.60	10.80
2x2	5559-4R	4.20	9.80	15.00
2x3	5559-6R	8.40	14.00	19.20
2x4	5559-8R	12.60	18.20	23.40
2x5	5559-10R	16.80	22.40	27.60
2x6	5559-12R	21.00	26.60	31.80
2x7	5559-14R	25.20	30.80	36.00
2x8	5559-16R	29.40	35.00	40.20
2x9	5559-18R	33.60	39.20	44.40
2x10	5559-20R	37.80	43.40	48.60
2x11	5559-22R	42.00	47.60	52.80
2x12	5559-24R	46.20	51.80	57.00

点击次数：1804 发布时间：2010-6-14 [【打印】](#) [【返回】](#)

