

MLZ2012A1R0WT000



用途	一般等级
特点	磁屏蔽
	积层
	铁氧体磁芯
系列 型	MLZ
状态	量产体制
品牌	TDK



尺寸

长度(L)	2.00mm ± 0.20mm
宽度(W)	1.25mm ± 0.20mm
厚度(T)	0.85mm ± 0.20mm
推荐焊盘布局(A)	0.80mm Nom.
推荐焊盘布局(B)	1.00mm Nom.
推荐焊盘布局(C)	1.20mm Nom.

电气特性

电感	1 μ H ± 20% at 10MHz
额定电流(基于L变化) [Typ.]	
额定电流(基于L变化) [Max.]	280mA (50% Down)
额定电流(基于温度上升) [Typ.]	900mA (20 ° C Rise)
额定电流(基于温度上升) [Max.]	280mA (20 ° C Rise)
直流电阻 [Typ.]	100m
直流电阻 [Max.]	130m
自己共振频率 [Min.]	
自己共振频率 [Typ.]	
Q [Min.]	
Q [Typ.]	

其他

使用温度范围(包括自我温度上升)	-55 ~ 125 ° C
焊接方法	流体
	回流
	烙铁焊接
AEC-Q200	No
包装形式	纸编带 (180mm卷筒)
包装个数	4000pcs

Images are for reference only and show exemplary products.

This PDF document was created based on the data listed on the TDK Corporation website.







! All specifications are subject to change without notice.

 重量
 0.01g

MLZ2012A1R0WT000



特性图表(这是参考数据，并不保证产品的特性。)

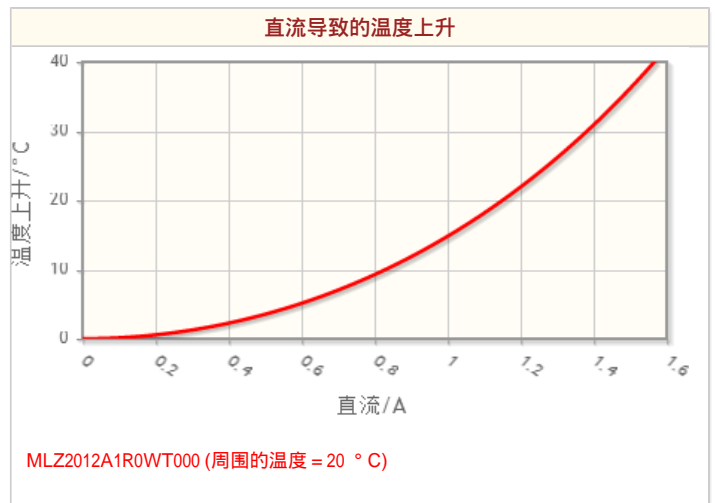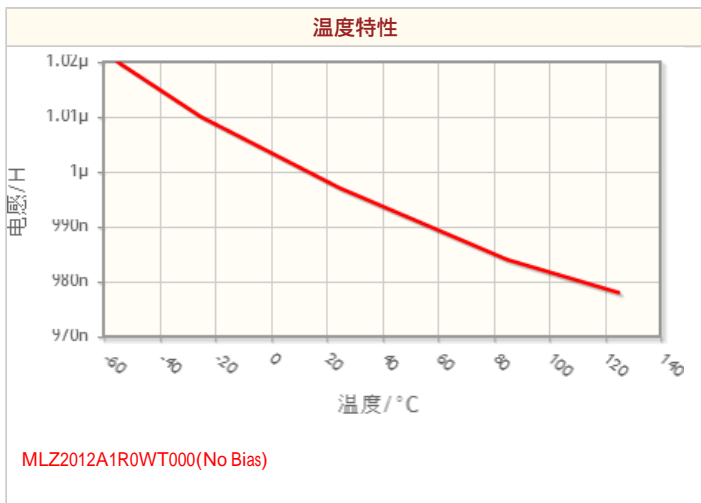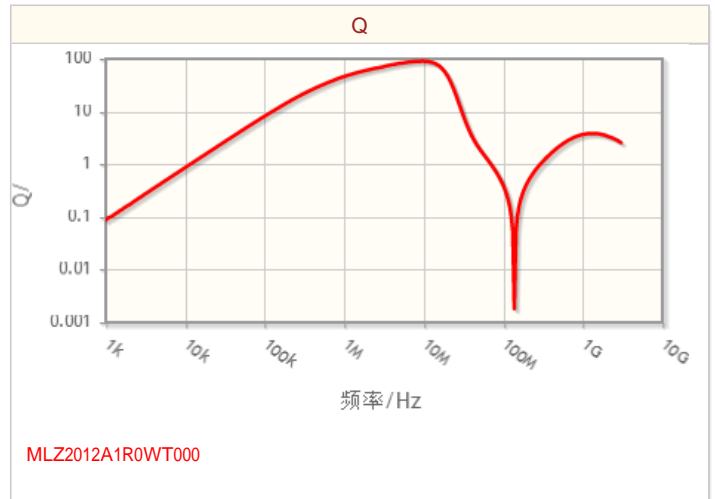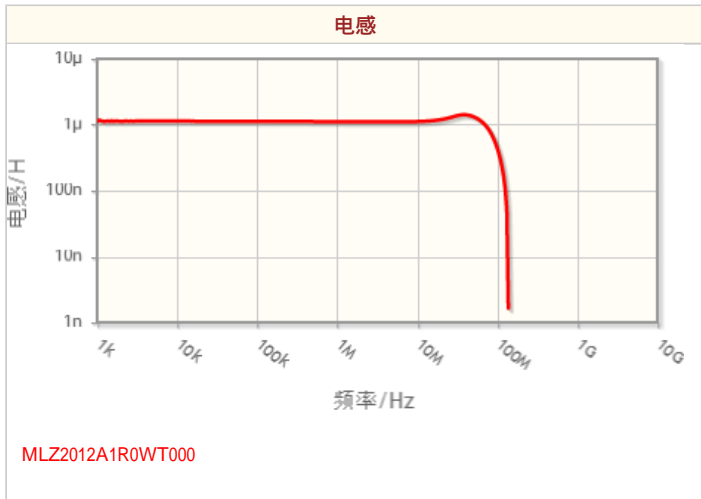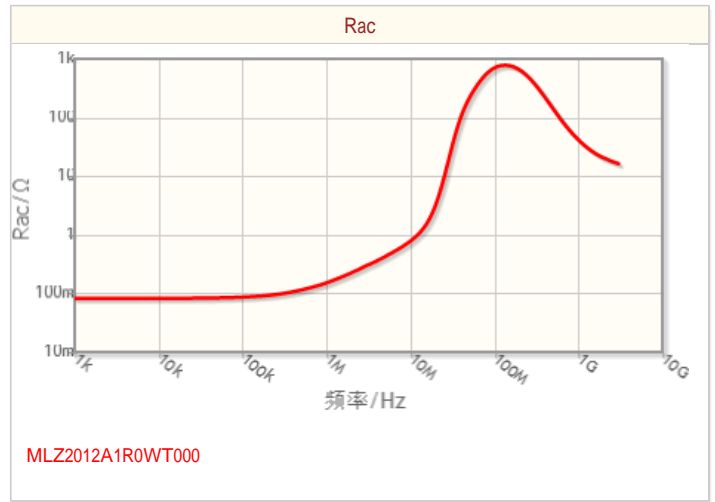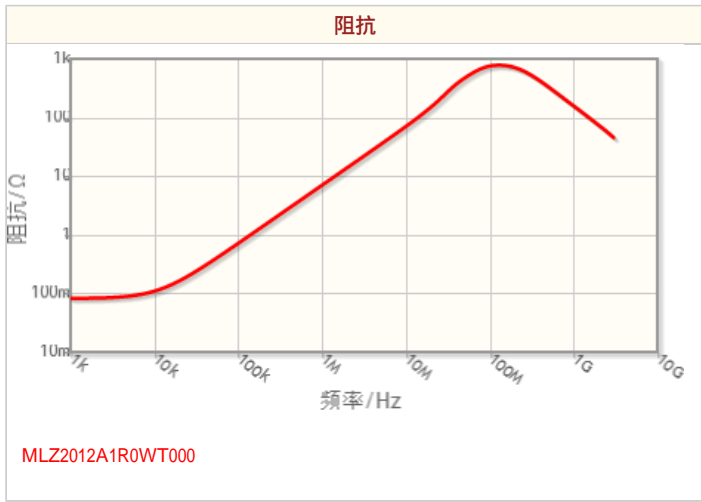


! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.

MLZ2012A1R0WT000



Associated Images

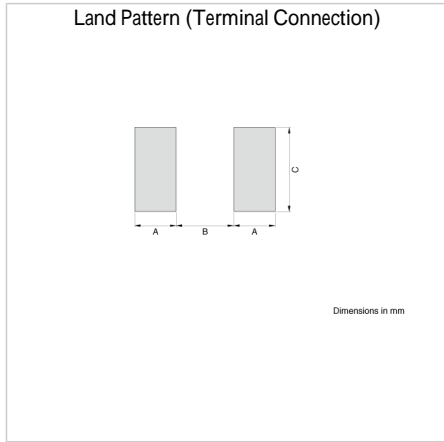

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.