
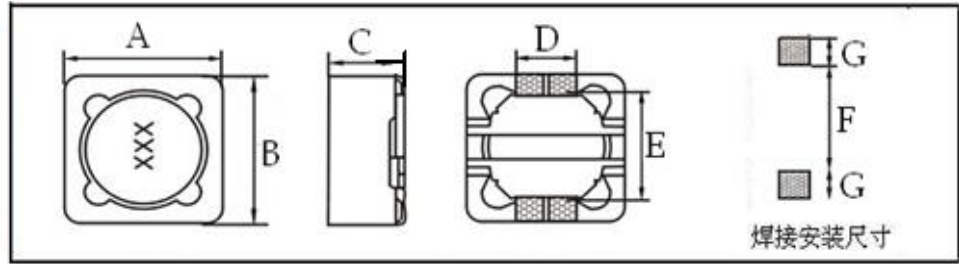


Anruike 安瑞科 / SMD POWER INDUCTORS CDRH105 SERIES

外型及尺寸 Shape and size (unit: mm)

Anruike/安瑞科

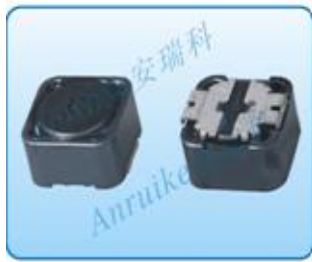

产品型号	A±0.3	B±0.3	C (MAX)	D	E	F	G	载带盘装
CDRH105	10.0	10.0	5.5	4.6	6.4	6.2	1.7	1000PCS/R

电气性能 Electrical properties

Anruike/安瑞科

产品型号	电感量 (uH)	公差 (%)	测试频率	直流电阻 RDC (Ω) (Max)	额定电流 IDC (A) (Max)
CDRH105-100M	10	±20	100KHz/0.25V	0.050	5.00
CDRH105-120M	12	±20	100KHz/0.25V	0.055	4.76
CDRH105-150M	15	±20	100KHz/0.25V	0.059	4.65
CDRH105-180M	18	±20	100KHz/0.25V	0.066	4.50
CDRH105-220M	22	±20	100KHz/0.25V	0.071	3.00
CDRH105-270M	27	±20	100KHz/0.25V	0.090	2.35
CDRH105-330M	33	±20	100KHz/0.25V	0.110	2.20
CDRH105-390M	39	±20	100KHz/0.25V	0.150	2.10
CDRH105-470M	47	±20	100KHz/0.25V	0.170	1.80
CDRH105-560M	56	±20	100KHz/0.25V	0.200	1.70
CDRH105-680M	68	±20	100KHz/0.25V	0.220	1.53
CDRH105-820M	82	±20	100KHz/0.25V	0.256	1.32
CDRH105-101M	100	±20	100KHz/0.25V	0.350	1.20
CDRH105-121M	120	±20	100KHz/0.25V	0.400	1.10
CDRH105-151M	150	±20	100KHz/0.25V	0.435	0.98
CDRH105-181M	180	±20	100KHz/0.25V	0.600	0.90
CDRH105-221M	220	±20	100KHz/0.25V	0.820	0.85
CDRH105-271M	270	±20	100KHz/0.25V	0.922	0.73
CDRH105-331M	330	±20	100KHz/0.25V	1.050	0.65
CDRH105-391M	390	±20	100KHz/0.25V	1.320	0.60
CDRH105-471M	470	±20	100KHz/0.25V	1.455	0.50
CDRH105-561M	560	±20	100KHz/0.25V	1.700	0.45
CDRH105-681M	680	±20	100KHz/0.25V	1.905	0.40
CDRH105-821M	820	±20	100KHz/0.25V	2.240	0.35
CDRH105-102M	1000	±20	100KHz/0.25V	2.355	0.30

以上为常用参数,精准参数以样品为准。本页面未能全部录入,需更多参数或特殊要求请联系我司

深圳市安瑞科电子有限公司 优质功率电感专业生产商. Tel:0755-29805463 27994543 FAX:0755-29805221

网址:<http://www.anruike.com> E-mail: anruike@anruike.com QQ:1193940818