

Specification

Insulator Material: Polyester, UL94V-0
Standard: NY-6T

Contact Material: Brass




Contact plated: Gold Over Nickel

Current Rating : 1.5Amp

Insulation Resistance : 1000M Ω Min.


Dielectric withstanding Voltage: AC 500V

Operation Temperature : -40 $^{\circ}$ C -- +105 $^{\circ}$ C

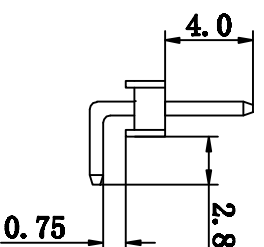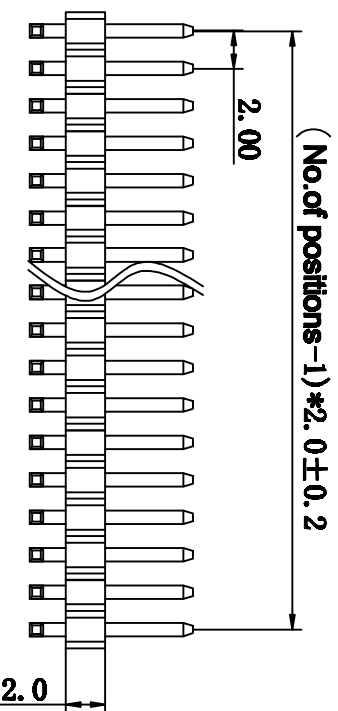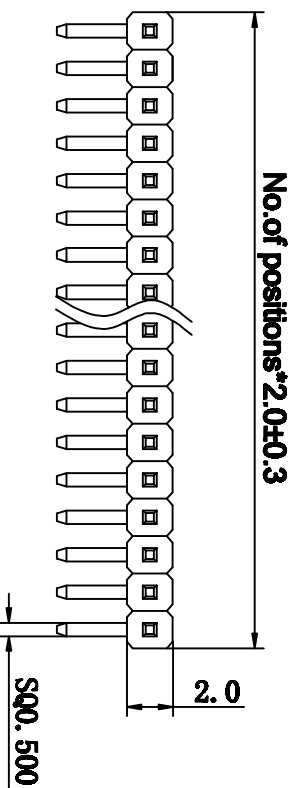

TOLERANCE TABLE

| | |
|------|-------|
| .0 | ±0.20 |
| .00 | ±0.10 |
| .000 | ±0.05 |

| | | |
|--------------|------------|---|
| APPROVED: | DATE: |  深圳市灿科盟实业有限公司 CHANKEMENG INDUSTRY CO., LTD |
| CHECKED: | DATE: | |
| DRAWN: | DATE: | TITLE: |
| LXF | 2008-04-29 | 210-2R-1*XP 4.0/2.0/2.8 |
| CLIENT P/N / | | UNIT mm |
| SCALE free | | FILE NO. Chantw-210-20004 |
| REV. A | | |