
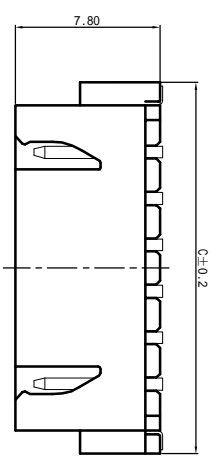
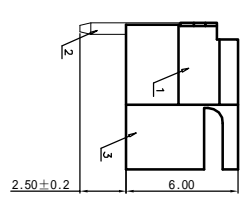


5		6	
版次	日期	内 容	
A1	10.06.10		


- Electrical properties:
- 1 Current rating:3 AC/DC (AWG #22)
 - 2 Voltage rating: 250V AC/DC
 - 3 Temperature range: -25°C to +85°C
 - 4 Contact resistance:Initial value/20mΩ max
 - 5 Insulation resistance:1000MΩ min
 - 6 Withstanding voltage:1000V AC / minute
 - 7 Applicable wire:AWG #26 to #22
- Environmental controls:
- 1 Banned contains SS - 00259 are restricted substances.
 - 2 The corresponding issued by SGS or ITS ICP-aes data.
- Not the material in a list, and validity.

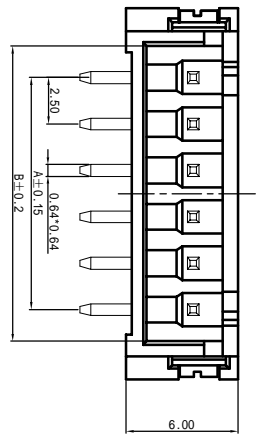

孔位 poles	A	B	C
2	2.5	5.9	10.0
3	5.0	8.4	12.5
4	7.5	10.9	15.0
5	10.0	13.4	17.5
6	12.5	15.9	20.0
7	15.0	18.4	22.5
8	17.5	20.9	25.0
9	20.0	23.4	27.5
10	22.5	25.9	30.0
11	25.0	28.4	32.5
12	27.5	30.9	35.0
13	30.0	33.4	37.5
14	32.5	35.9	40.0
15	35.0	38.4	42.5
16	37.5	40.9	45.0

3	003	基 座	LCP(EI130)	1	
2	002	接 触 件	黄 铜	N*	镀锡
1	001	焊 片	磷青铜	2	镀锡
序号	图 号	名 称	材 料	数 量	附 件

尺寸公差	角度公差	品 名:	CF.XH-AB	审 核	章 松
X. ±0.3	.X° ±0.1°	图 号:	CF.GG.XH.020	批 准	周伟国
.X ±0.2	.XX° ±0.05°	比例:	--	页 数:	1/1
.XX ±0.15	.XXX° ±0.005°	单 位:	mm	版 本:	A

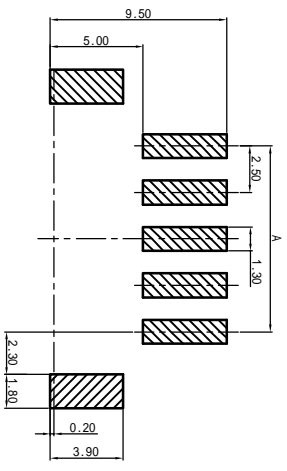

安装 P.B.C 板
Recommended P.B.C.Layout

