

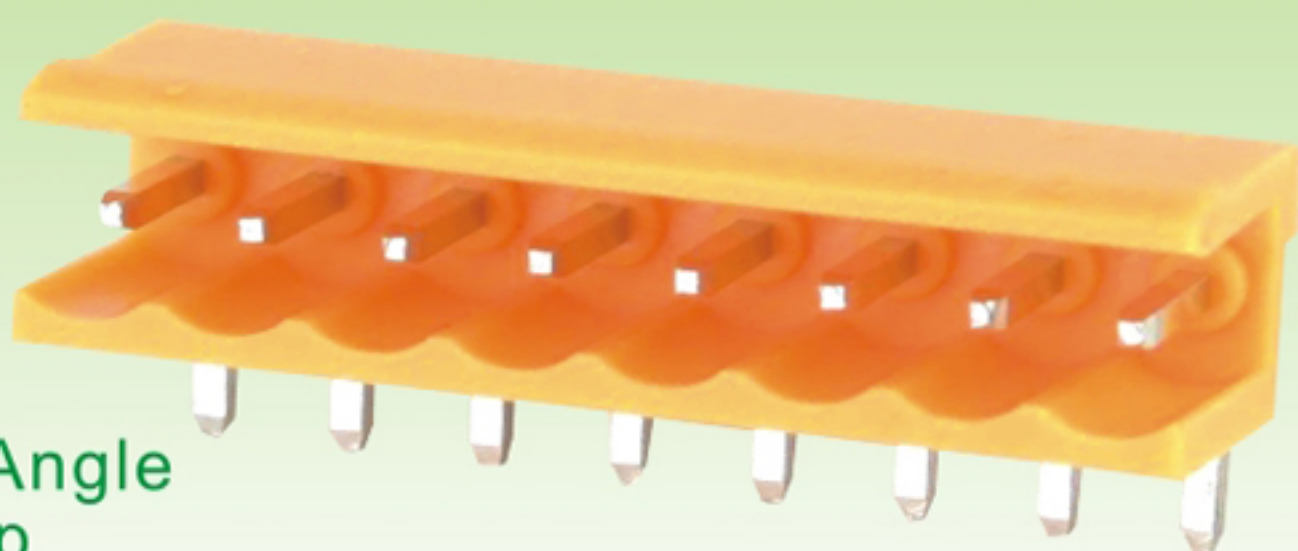
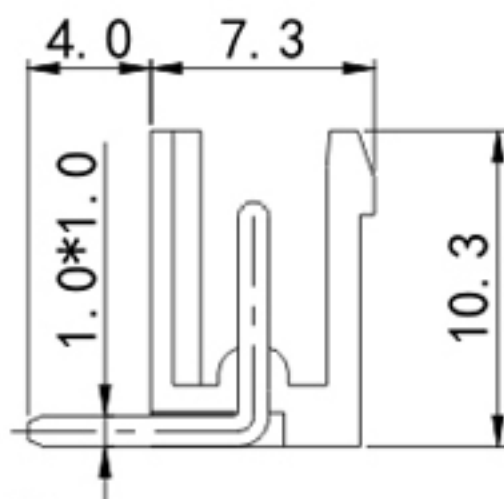


# WJHT396R

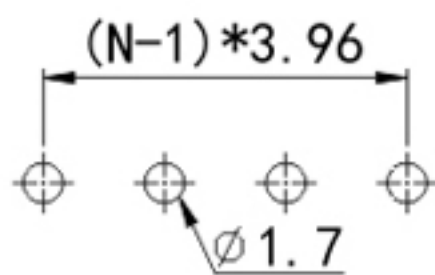

Open Right-Angle  
Poles 2p~24p  
Number of poles

Screws (螺丝)	:
Wire guard (簧片)	:
Pin header (焊针)	:Brass, Tin plated
Housing (塑件)	:PA66, UL94V-0
Rated voltage (额定电压)	:300V
Rated current (额定电流)	:16A
Contact resistance (接触电阻)	:20mΩ
Insulation resistance (绝缘电阻)	:5000MΩ/DC1000V
Withstanding Voltage (耐电压)	:AC1500V/1Min
Wire range (使用线径)	:
Temp.Range (温度范围)	:-40°C~+105°C
Torque (扭矩)	:
Strip length (剥线长度)	:

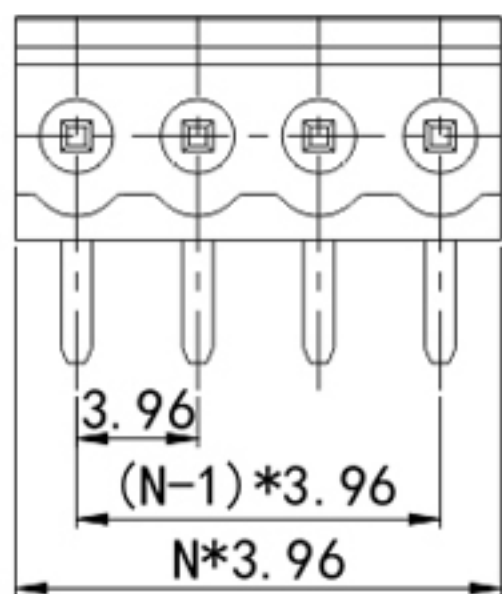

Pitch:3.96mm