



BST-21

线切割供应商BST-21

- ▶ 品牌名称: BEST
- ▶ 型号: BEST-21
- ▶ 类型: 对角线钳子/切割钳
- ▶ 材料: 铬钒
- ▶ 材质: Cr-V钢+ PVC手柄涂层
- ▶ 表面处理: 防锈油
- ▶ 尺寸: 135毫米
- ▶ 包: 12个/箱
- ▶ N.W.: 101g / pc
- ▶ G.W.: 1.42kg / 盒



[Contact Now](#)

Features

材料: Cr-v钢刀片和PVC手柄
 表面处理: 抛光, 黑色, 镀铬, 染色, 镍大
 手柄: 单色PVC / TPR手柄

Specification

模型:	BEST-21剪线钳
材料:	Cr-V钢+ PVC手柄涂层
热处理:	身体酸化42-50HRC 刀片高频54-62HRC
表面处理:	防锈油
尺寸:	135毫米
包:	12支/盒
N.W.	101克/ PC
毛重:	1.42公斤/盒

PRODUCT DISPLAY



PRODUCT SIZE

Name: Diagonal cutting pliers

Model: BST-21

Material: 60CR-V

Brand: BEST

Hardness: HRC38-42

Blade Hardness: HRC56-62


Size: 125mm

Weight: 100g

Range: HRC20

below: hard wire Φ 1.5mm, copper wire
or aluminum wire Φ 0.1-2.0mm

Process: using repeated forging,
the surface is polished after grinding
and processing by precision machining.

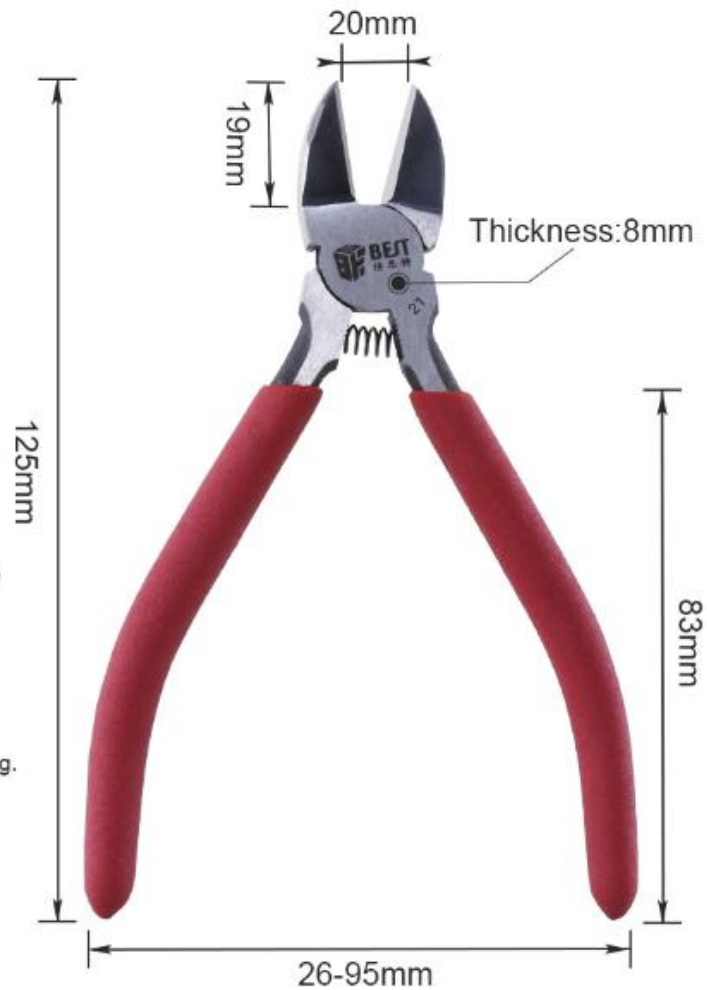

PRODUCT DETAILS



Cutting range

- HRC20 below: hard wire Φ 1.5mm, copper wire or aluminum wire Φ 0.1-2.0mm
- Made of high quality alloy steel CR-V
- For family, electronic maintenance, manufacturing and other industries

PRODUCT PHOTOGRAPH



User manual

⚠ Warning

This model is not insulated tools. Please use it when power off.

⚠ Attention

- To protect user safe, please use protective glasses.
- As the cut material will fly out, make sure no one beside you and no easy damaged things beside you, then begin working.
- This product is not a dedicated pressure equipment.
- When stored, please assure the blade at the closed state and can not be touched by children.
- Do not let the plier tip rub something.
- Please do not directly touch the blade part with hand.
- Do not use in cutting hard materials and steel wire, etc.
- Do not use the pliers above its cutting capability and coarse wire.

PRODUCT PACKAGING

WEIGHT:98G



FRONT



FRONT