



对角线切割钳Cr-V重型切割钳迷你尺寸BEST-4

- ▶ 型号: BST-4斜切钳
- ▶ 材质: Cr-V钢+ PVC手柄涂层
- ▶ 热处理: 酸化42-50HRC身体;高频54-62HRC刀片
- ▶ 表面处理: 防锈油
- ▶ 尺寸: 108毫米
- ▶ 包装: 12支/盒
- ▶ N.W.101g / PC

[Contact Now](#)



Features

1. 对角切割钳由Cr-V钢制成, 可用于重型作业。
2. 高频淬硬精密切削刃, 硬度HRC54-62
两个彩色PVC手柄与手指保护
- 4.5"的大小
5. 达到或超过CE标准

Specification

模型:	BEST-4斜切钳
材料:	Cr-V钢+ PVC手柄涂层
热处理:	身体酸化42-50HRC 刀片高频54-62HRC
表面处理:	防锈油
尺寸:	135毫米
包:	12支/盒
N.W.	101克/ PC
毛重:	1.42公斤/盒

Application

斜切钳通常用于切割各种细线, 引线, 软线, 电路板, 塑料边角料等
工业机器人控制箱接线。
IC印刷电路板和电脑配线
家用电器。
收音机和其他电话和电报线路。
汽车电路。
其他精密配线D.I.Y项目。

PRODUCT DISPLAY



PRODUCT SIZE

Material:high quality alloy steel(60CR-V)

Process:using repeated forging,the surface is polished after grinding and processing by precision machining

Hardness:the overall hardness is HRC38-42 the blade hardness is HRC56-62

Shear capacity:HRC20 below

Hard wire Φ 1.5mm

soft copper wire,aluminum wire Φ 0.1-2.0mm




PRODUCT DETAILS



Front



Back side

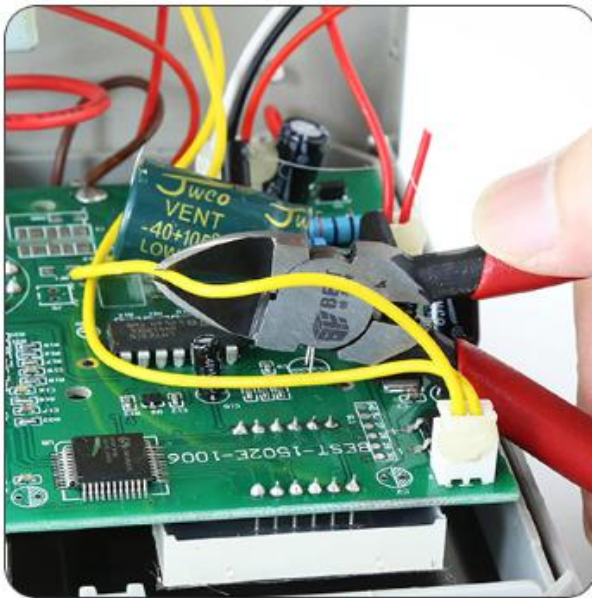

User manual


Warning

This model is not insulated tools. Please use it when power off.

Attention

- To protect user safe, please use protective glasses.
- As the cut material will fly out, make sure no one beside you and no easy damaged things beside you, then begin working.
- This product is not a dedicated pressure equipment.
- When stored, please assure the blade at the closed state and can not be touched by children.
- Do not let the plier tip rub something.
- Please do not directly touch the blade part with hand.
- Do not use in cutting hard materials and steel wire, etc.
- Do not use the pliers above its cutting capability and coarse wire.

PRODUCT PHOTOGRAPH

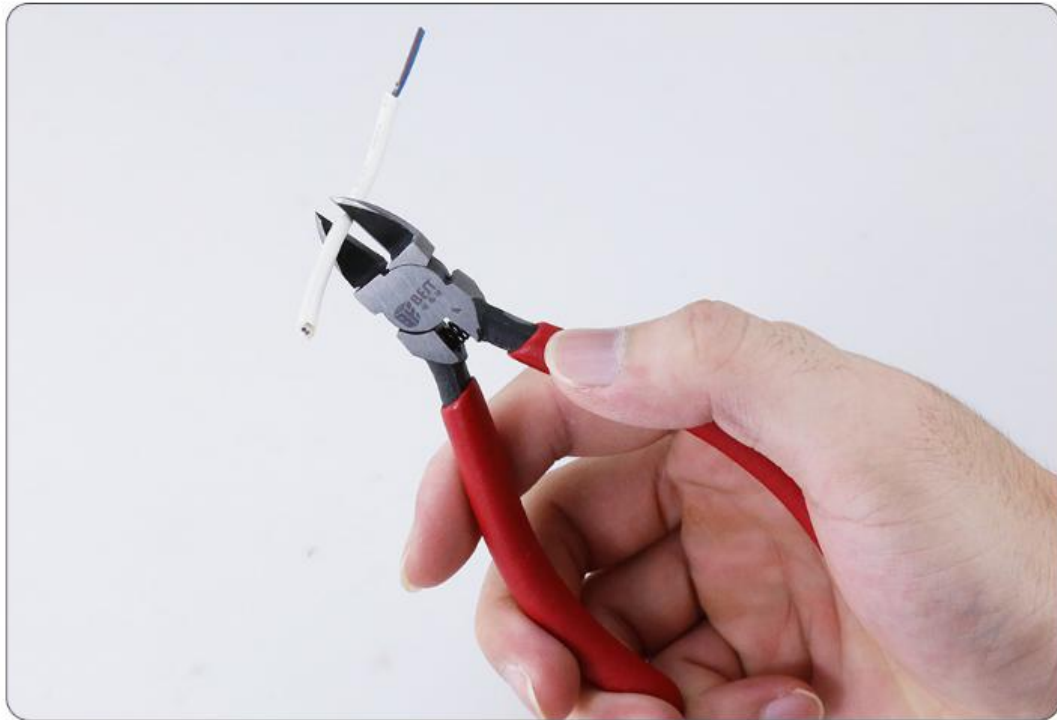

PRODUCT PACKAGING

WEIGHT:82G



180MM

FRONT

75MM



BACK