




### 1107 KSS PC板隔离顶柱



**材质：** UL合格之NYLON 66（本色），防火等级 94V-2。

**用途：** 支撑 PC板用，增加 PC板稳定。

**用法：** 先将基板钻孔 4.8mm，再将隔离顶柱插入基板孔即可。

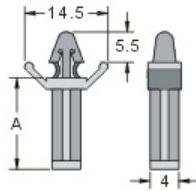

| 单位：mm                    |                 |         |        |     |                |
|--------------------------|-----------------|---------|--------|-----|----------------|
|                          | 型 号<br>Item No. | 间距<br>A | 适用PCB板 |     | 包 装<br>Packing |
|                          |                 |         | 钻孔     | 板厚  |                |
| <input type="checkbox"/> | PS-5            | 4.8     | 4.8    | 2.0 | 100 pcs / 包    |
| <input type="checkbox"/> | PS-6            | 6.4     | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-10           | 9.6     | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-13           | 12.7    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-16           | 15.9    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-19           | 19.1    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-22           | 22.2    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-25           | 25.4    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-28           | 28.5    | 4.8    | 2.0 |                |
| <input type="checkbox"/> | PS-36           | 35.0    | 4.8    | 2.0 |                |

放入选样单

查看选样单

退回所有选样

