




Miniature Slide Switches

Specifications:

| | |
|------------------------|---|
| Contact rating: | 30 V DC, 350 mA |
| Contact resistance: | < 20 mΩ |
| Insulation resistance: | > 100 MΩ at 500 V DC; MFPP 130 – RA: 250 V DC |
| Dielectric strength: | 500 V, 50 Hz for the duration of 1 minute |
| Operating temperature: | –20 °C to +85 °C |
| Mechanical life: | minimum 10 000 operations |
| Contacts: | copper alloy, silver-plated over nickel barrier |
| Slide colour: | black, further colours on request |
| Soldering conditions: | wave-soldering – max.: 5 sec, 260 °C ± 5 °C |

Models: Switching functions

MFP 121 D – RA on on non-shorting

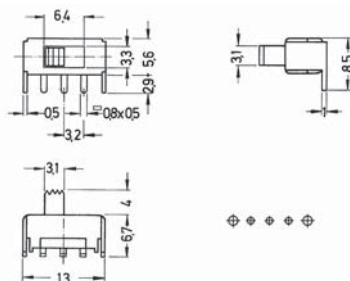

MFP 201 N – RA on on non-shorting

