

**SEA&LAND ELECTRONIC CORP.**

13F., No.120-10,  
 Sec. 3, Zhongshan Rd., Zhonghe Dist., New Taipei City 235,  
 Taiwan  
 Tel.: 886-2-8221-2567  
 Fax.: 886-2-2225-7268

**Techfuse**  
**PTC Devices**  
 Resettable Fuse

PRODUCT: SMD0603-010-24V  
 DOCUMENT: QR0429  
 ECN. NO.:  
 REV LETTER: C  
 REV DATE: 2015/1/23  
 PAGE NO.: 1 of 1

# Specification Sheet

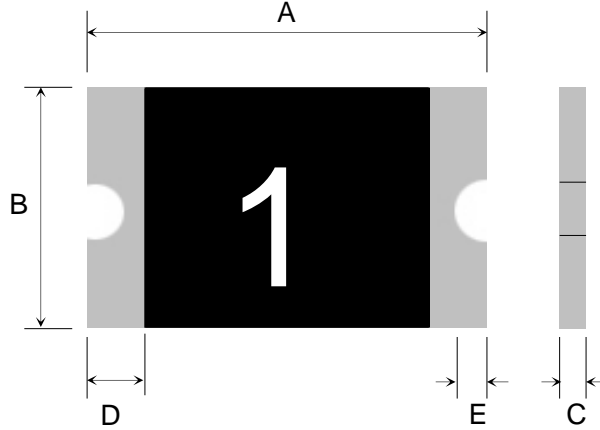
Terminal Pad Solderability:  
 Meets EIA Specification RS186-9E  
 And ANSI/J-STD-002 Category 3.

Terminal Pad Materials:  
 Tin-plated Nickel-Copper

Lead-Free, RoHS Compliant

**Marking:**

Part Identification  
 1= 010

**TABLE I. DIMENSIONS:**

Model	Marking	A		B		C		D	E
		Min.	Max.	Min.	Max.	Min.	Max.	Min.	Min.
SMD0603-010-24V	1	1.45	1.85	0.65	1.05	0.40	1.00	0.15	0.10

Unit:mm

**TABLE II. PERFORMANCE RATINGS:**

Model	Marking	$V_{max}$ (Vdc)	$I_{max}$ (A)	$I_{hold}$ @25°C (A)	$I_{trip}$ @25°C (A)	$P_d$ Typ. (W)	Maximum Time To Trip		Resistance	
							Current (A)	Time (Sec)	$R_{i_{min}}$ (Ω)	$R_{1_{max}}$ (Ω)
SMD0603-010-24V	1	24.0	40	0.10	0.30	0.50	0.5	1.00	0.900	10.000

**Order Information****Packaging**

SMD0603	010	-24V	Tape & Reel Quantity
Product name	Hold	Max	5,000 pcs/reel
Size 1508 mm / 0603 mils	Current	voltage	
SMD: surface mount device	0.10A		

Recognition: UL Pending.