

**SPECIFICATION:**

Current Rating: 3.0AMP  
 Contact Resistance: 20m Ω (max)  
 Insulation Resistance: 1000M Ω Min at 500V DC  
 Dielectric Strength: 500V AC Per 1 Minute  
 Operating Temperature: -40 °C TO +105 °C

**MATERIALS:**

Insulator: P.B.T.+30% Glass Fibre(UL 94V-0)  
 Contact: Brass  
 Contact plated: 0.8u" Gold Over Nickel

Poles	Part No.	Dimension mm		
		A	B	C
10	310R-10P	31.90	10.16	18.60
12	310R-12P	34.44	12.70	21.14
14	310R-14P	36.98	15.24	23.68
16	310R-16P	39.52	17.78	26.22
20	310R-20P	44.60	22.86	31.30
24	310R-24P	49.68	27.94	36.38
26	310R-26P	52.22	30.48	38.92
30	310R-30P	57.30	35.56	44.00
34	310R-34P	62.38	40.64	49.08
40	310R-40P	70.10	48.26	56.70
50	310R-50P	82.70	60.96	69.40
60	310R-60P	95.40	73.66	82.10
64	310R-64P	100.48	78.74	87.18

**TOLERANCE TABLE**

.0	±0.30
.00	±0.20
.000	±0.05

APPROVED:

DATE:

CHECKED:

DATE:

DRAWN:

DATE:

LYP

2008-04-07

TITLE:

310R-XP


深圳市矽科盟实业有限公司  
 KIMT CHANKEMENG INDUSTRY CO., LTD

CLIENT P/N /

UNIT	mm	SCALE	Free	REV.	A
FILE NO.	Chantw-310-00003				

**深圳市灿科盟实业有限公司**  
**SHENZHEN CHANKEMENG INDUSTRY CO., LTD**

## 筒牛、牛角成品编码规则

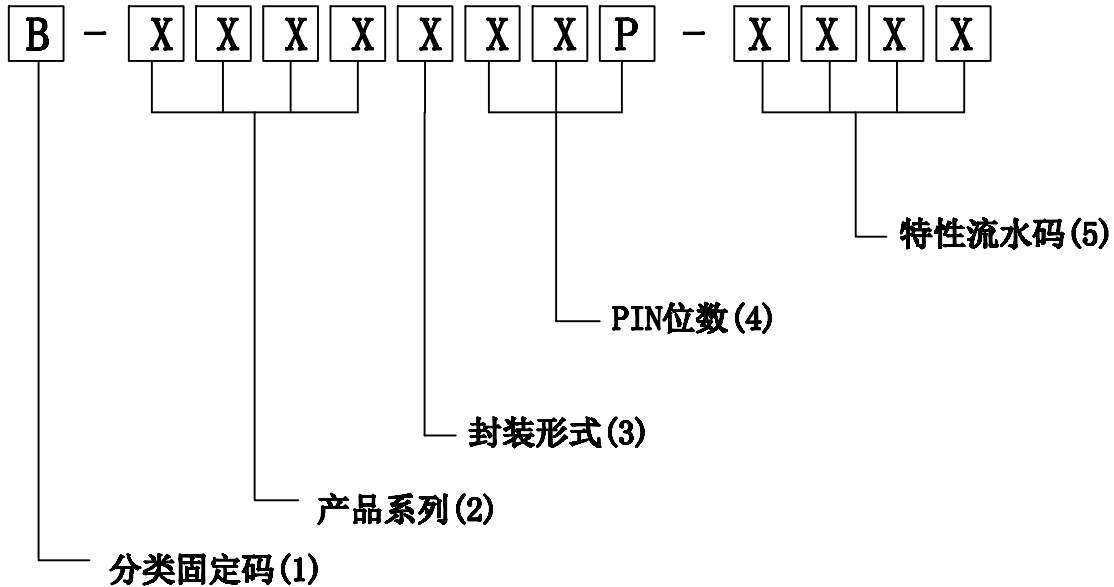

**说明:**

- (1). 此位数为分类固定码“B”-连接器
- (2). 此数为产品系列,

编码	品名	规格描述
3000	300	筒牛/2.54mm
3001	300-1	筒牛/1.27mm
3002	220-2	筒牛/2.0mm

编码	品名	规格描述
3100	310	牛角/2.54mm
3101	310-1	牛角/1.27mm
3102	310-2	牛角/2.0mm

- (3). 封装形式:

S	直插
R	弯插
M	卧贴
N	立贴

- (4). PIN位数

按实际PIN数编码, 100用“A0”

如: 100位, 编码为“A0P”

- (5). 特性流水码

在规格/描述中, 按步骤指定:

- a) 结构尺寸特性
- b) 塑胶材料特性(颜色+材质)
- c) 五金材料特性(材质+镀层)
- d) 其它特定要求

批 准: \_\_\_\_\_

审 核: \_\_\_\_\_

制 定: 龙永峰