

Material:
 Insulator: PBT+30% Glass Fiber (UL94V-0).
 Contact: Copper Alloy.
 Contact Plated: Gold or Tin over Nickel Plated.
 Specification:
 Current Rating: 1 Amp.
 Withstanding Voltage: AC 500V for 1 Minute.
 Insulation Resistance: 1000MΩ Min. at DC 500V.
 Contact Resistance: 15mΩ Max.
 Operating Temperature: -40°C ~ +105°C.

Contact Material: Brass

Pos.	Dim. A	Dim. B	Dim. C	Dim. D
10	10.16	18.15	22.95	11.43
14	15.24	22.94	28.03	16.51
16	17.78	25.48	30.57	19.05
20	22.86	30.56	35.65	24.13
24	27.94	35.64	40.73	29.21
26	30.48	38.18	43.27	31.75
30	35.56	43.26	48.35	36.83
34	40.64	48.34	53.43	41.91
40	48.26	55.96	61.05	49.53
50	60.96	68.66	73.75	62.23
60	73.66	81.36	86.45	74.93
64	78.74	86.44	91.53	80.01


TOLERANCE TABLE

.0	±0.30
.00	±0.20
.000	±0.05

APPROVED:	DATE:	C 深圳市灿科盟实业有限公司 CHANKEMENG INDUSTRYCO., LTD
CHECKED:	DATE:	
DRAWN:	DATE:	TITLE: 300F-XP 压线式 无耳 灰白色
SXA	2019-04-27	CLIENT P/N: B-3000FXXP-0800
		UNIT: mm SCALE: free
		FILE NO: Ckmtw-300-0009 REV. Q700

深圳市灿科盟实业有限公司
SHENZHEN CHANKEMENG INDUSTRY CO., LTD

IDC编码规则

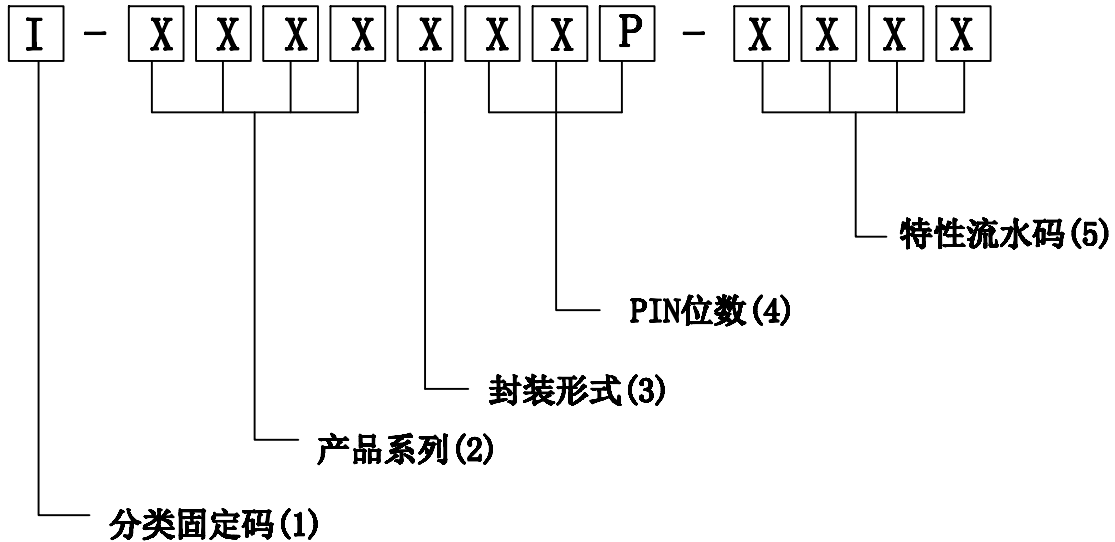

说明:

- (1). 此位数为分类固定码“I”-IDC连接器
- (2). 此数为产品系列,

编码	品名	规格描述
1010	101	FC/2.54mm
1011	101-1	FC/1.27mm
1012	101-2	FC/2.0mm
6030	603	FD/2.54mm
6032	603-2	FD/2.0mm

编码	品名	规格描述
300F	300F	筒牛IDC/2.54mm
310F	310F	牛角IDC/2.54mm

- (3). PIN位数
按实际PIN数编码, 100用“A0”
如: 100位, 编码为“A0P”

- (5). 特性流水码
在规格/描述中, 按步骤指定:
a) 结构尺寸特性
b) 塑胶材料特性
c) 五金材料特性
d) 其它特定要求

- (4). 封装形式:

1	反折扣 (单件)
2	二件式
3	三件式

批 准: _____

审 核: _____

制 定: 龙永峰