

SPECIFICATIONS

Rated(额定参数): 300V,20A
 Dielectric strength(抗电强度): AC2000V/1 Minute
 Insulation Resistance(绝缘电阻):1000MΩ Min
 Contact Resistance(接触电阻):20mΩ Max
 Screw Torque(扭矩): 0.5Nm (4.4l.b.in)
 Wire Range(线径):14~22AWG
 Temp. range(操作温度): -40℃~+105℃
 MAX Soldering(瞬时温度):+250℃,5s


Housing Material(塑件): PA66 (UL94 V-0)
 Contact(端子): Brass, Tin plating(黄铜镀锡)
 Screw (螺丝): M3.0, Steel, Ni plating(钢,镀锌)

| PITCH RANGE IN MM | NOMINAL DIMENSION RANGE IN MM | | | | |
|----------------------|----------------------------------|------------|------------|------------|------------|
| | OVER TO | OVER TO | OVER TO | OVER TO | OVER TO |
| 6 | 10 | 30 | 60 | 100 | OVER |
| 10 | 24 | 30 | 60 | 100 | 150 |
| ±0.10 | ±0.15 | ±0.25 | ±0.30 | ±0.50 | ±0.70 |
| | | | | | ±1.00 |

Ordering Information

JL850B - 850 XX X X 1

Pitch 850=8.5PH
 No.of pins 2P~24P
 Housing Color
 B=Black
 G=Green
 U=Blue
 R=Red
 W=White
 Y=Yellow
 O=Orange
 F=Grey
 Packing
 O=Pe bog
 T=Tube
 A=Troy

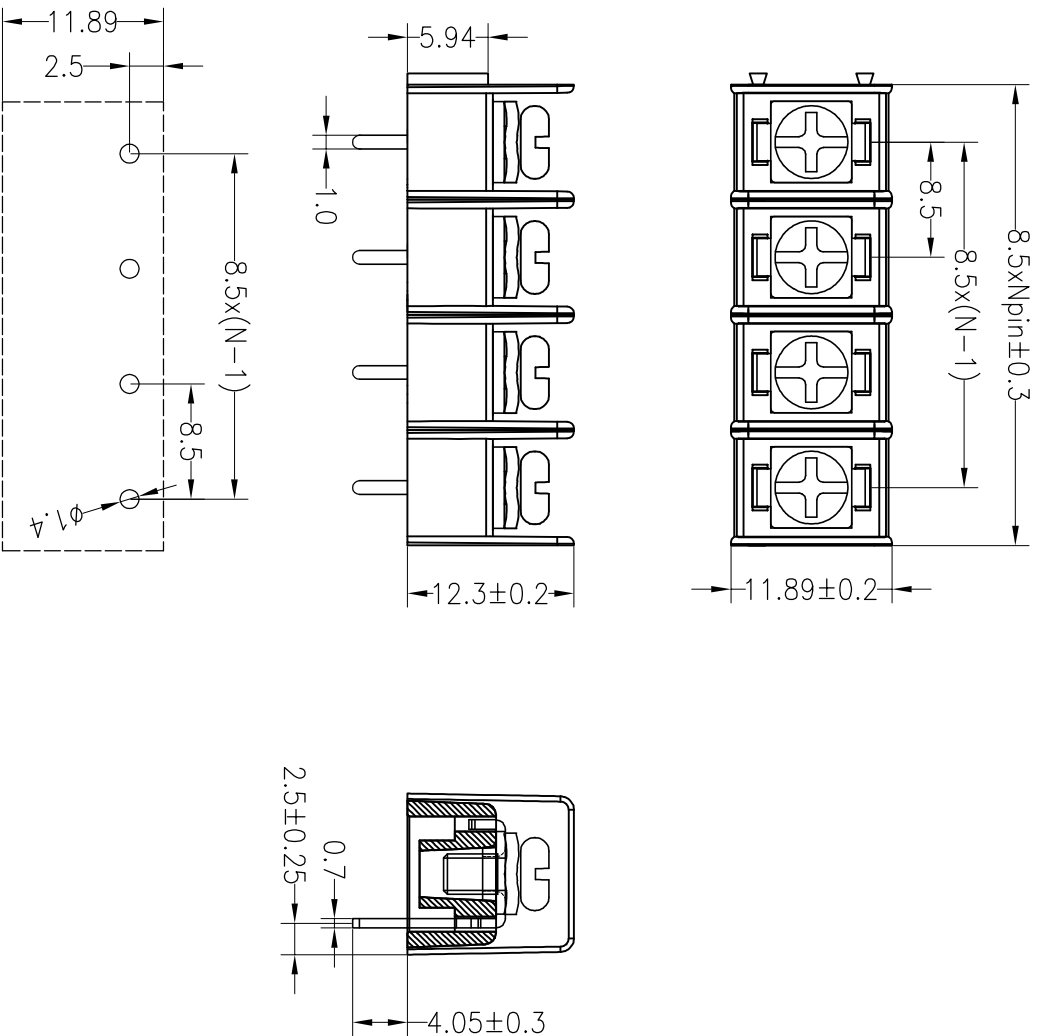

| OPERATION | | DRAW | | SCALE | FIT | PART NO. | |
|-----------|------------|--------------------------|-----------|-------|-----|------------------------------|-----------------|
| DIM | TOL | APPROVE | Yiyusheng | UNIT | mm | SIZE | JL850B-850XXXX1 |
| X.X | ±0.30 | CHECK | 18.10.07 | A4 | 1/1 | 8.5mm Terminal Blocks Female | |
| X.XX | ±0.20 | | | | | | |
| X.XXX | ±0.10 | | | | | | |
| Angle | ±3° | | | | | | |
| CHANGE | | | | | | | |
| REV | DATE | MODIFICATION DESCRIPTION | | | | | |
| 1 | 2018.10.07 | NEW DRAWING | | | | | |

JILN 深圳市锦凌电子有限公司
 SHENZHEN JINLING ELECTRONIC CO.,LTD
 Tel: 86-755-2997-5806/5802 Fax: 86-755-2997-5992