

HSF ROHS us CE

SPECIFICATIONS

Rated(额定参数): 150V,4A
 Dielectric strength(抗电强度): AC1250V/1 Minute
 Insulation Resistance(绝缘电阻):1000MΩ Min
 Contact Resistance(接触电阻):20mΩ Max
 Temp. range(操作温度): -40℃~+105℃
 MAX Soldering(瞬时温度):+250℃,5s

Housing Material(塑件): PA66 (UL94 V-0)
 Contact(端子): Brass, Tin plating(黄铜镀锡)

PITCH RANGE		NOMINAL DIMENSION RANGE	
IN MM		IN MM	
OVER	OVER	OVER	OVER
TO	TO	TO	TO
6	10	30	60
10	24	TO	TO
		60	100
		TO	TO
		100	150
		TO	TO
±0.10	±0.15	±0.25	±0.30
		±0.30	±0.50
		±0.50	±0.70
		±0.70	±1.00

Ordering Information




JL15EDGRC - XXX XX X X 1

Pitch
 250=2.50PH
 254=2.54PH

No.of pins
 2P~24P

Housing Color
 B=Black
 G=Green
 U=Blue
 R=Red
 W=White
 Y=Yellow
 O=Orange
 E=Grey

Packing
 O=Pe bag
 T=Tube
 A=Troy

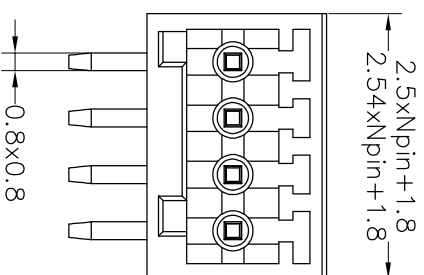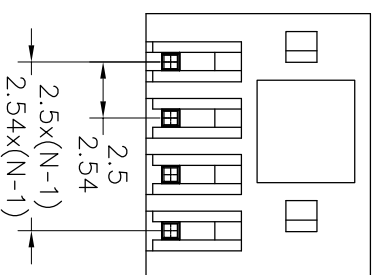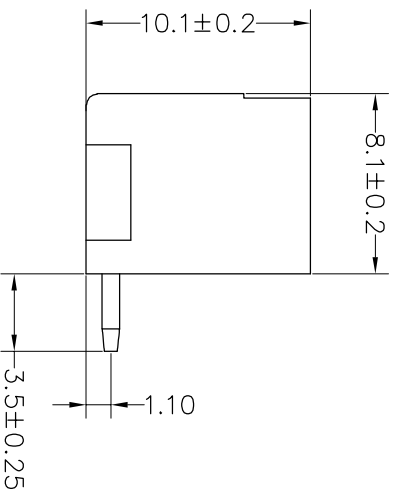

REV	DATE	MODIFICATION DESCRIPTION	CHANGE	DIM	TOL	APPROVE	OPERATION	DRAW	yiyusheng	17.01.05	SCALE	FIT	SIZE	SHEET	PROU.	PART NO.	TITLE:
A0	2017.01.05	NEW DRAWING		Angle	±3°	CHECK	XX	CHECK			UNIT	mm	A4	1/1		JL15EDGRC-XXXXXXXX1	2.50/2.54mm Pitch Male Plugqable Termindl Blocks
1							XX										

JIN 深圳市锦凌电子有限公司
 SHENZHEN JINLING ELECTRONIC CO.,LTD
 Tel: 86-755-2997-5806/5802 Fax: 86-755-2997-5992