

Cixi Dibo Electronics Co.,LTD

产品规格书

product specification



参考标准/Standard:	UL	IEC
额定电压/Rated voltage:	300V	320V
额定电流/Rated current:	15A	20A
接触电阻/Contact resistance:	20m Ω	
耐电压/Withstanding voltage:	AC2000V/1Min	
绝缘电阻/Insulation resistance:	500M Ω /DC500V	


温度范围/Temp.Range: -40° C~+105° C
瞬间温度/MAX Soldeting: +250° C, for 5 Sec

间距/Pitch: 5.00mm, 5.08mm

极 数/Poles: 2P-24P

塑 件/Housing: PA66, UL94V-0
焊 针/Pin header: Brass, Tin plated
螺 母/Nut: M2.5 Brass

订购方式：
HOW TO ORDER

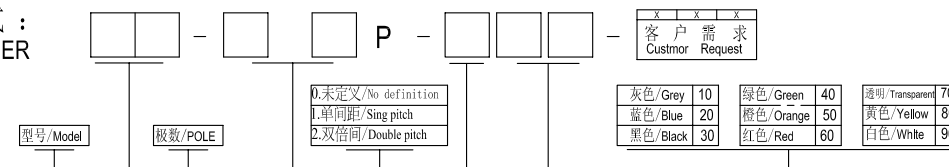

	linear dimension					fillet	chamfer		 short angle sid								
variable range	to 6	over 6 to 30	over 30 to 120	over 120 to 480	all	to 6	over 6 to 10	over 10 to 50	over 50 to 120	all	to 5	over 5 to 30	over 30 to 120	over 120 to			
tolerance	±0.1	±0.2	±0.3	±0.5	±0.9	±0.2	±0.5	±1	1'	30'	20'	10'	0.5	0.025	0.06	0.12	0.4

单位/UNITS	mm	尺寸/SIZE	A4	比例/SCALE		第一视角/FIRST ANGLE PROJECTION
Cixi Dibo Electronics Co.,LTD					名称/NAME	DB2ERM-5.08-XXP-