 


# JGHC<sup>®</sup> Y206 32.768KHZ




## Features

- Application for variety products reference clocks;
- reliable environmental performance;
- RoHS Compliant / Pb Free;

Frequency Range	32.768KHZ
Equivalent Series Resistance	40KΩMax.
Drive Level	1.0μWMax
Frequency Tolerance (at 25 °C)	± 10 ppm, ± 20 ppm, or specify
The inflection point temperature	+25°C± 5°C
Frequency temperature coefficient	-0.04 × 10 <sup>-6</sup> / °C <sup>2</sup> Max.
Operating Temperature Range	-10 ~ +60 °C, or specify
Shunt Capacitance (C0)	1.1 pF TYP
Load Capacitance	6pF, 12.5 pF, or specify
Aging (at 25 °C)	± 3 ppm / year Max.
Storage Temperature Range	-20~+70°C, or specify
Packing Unit(包装单位)	1,000pcs/Bag

## Dimensions

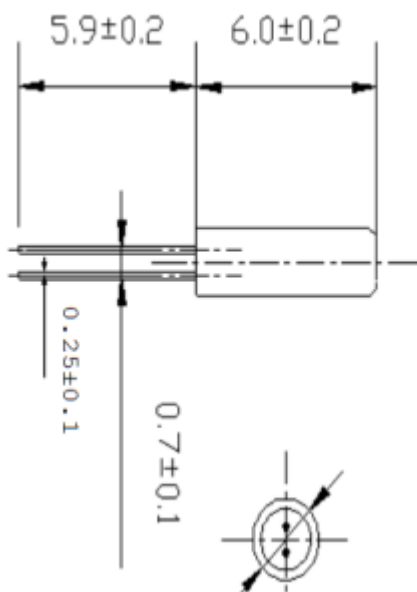

Units: mm