

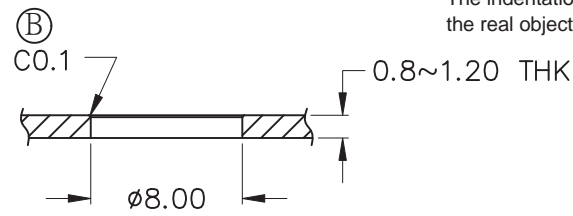
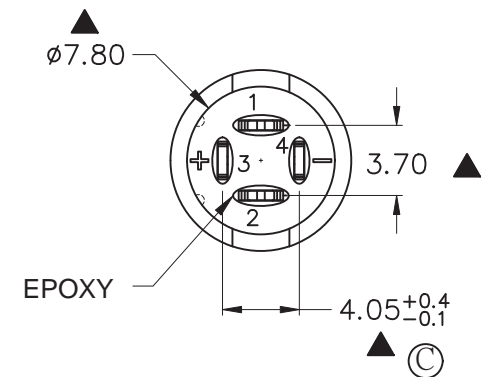



本公司智慧財產，未經同意不得複製
DAILYWELL copyright, may not be used
without permission from DAILYWELL

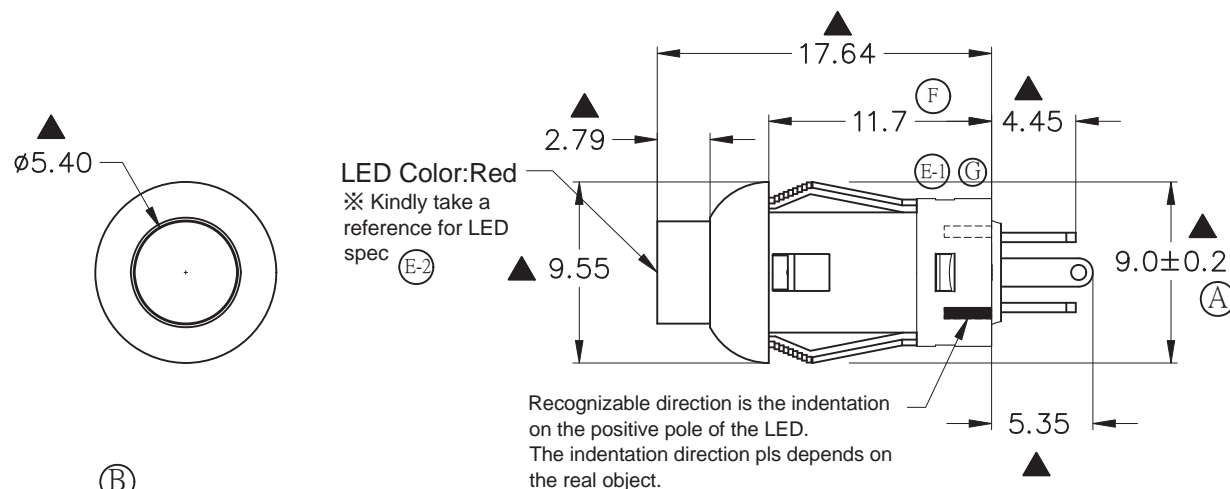

PANEL MOUNTING

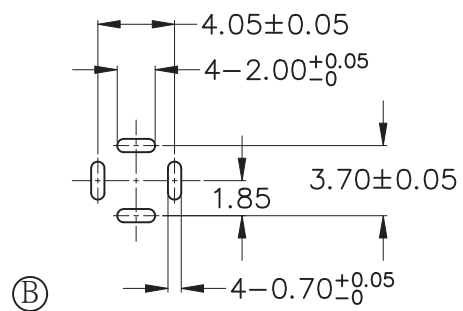

PCB MOUNTING

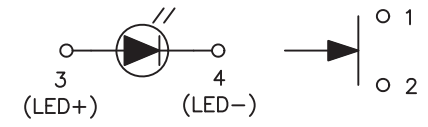

SWITCH FUNCTION

Specifications

- Pole-position : Momentary Type, SPST with LED
- Contact rating : 30V DC, 0.1A
- Contact resistance : 50 mΩ max. 1.5V DC ; 100mA, by Method of Voltage DROP
- Insulation resistance : 100 MΩ min. 500V DC
- Dielectric strength : 500V AC for 1 Minute
- Operating force 250±100gf
- Operating life : 50,000 cycles
- Operating temperature range : -40°C ~ 85°C
- Total travel : 1.2±0.3mm

Materials

- Cap : PC
- Case & Housing : Nylon 6/6
- Terminals : Copper alloy with gold plated.

符號	原尺寸	修改後尺寸	變更日期
1 (A)	外觀變9.55→9.0±0.2, PANEL MOUNTING Ø7.90→Ø8.00		MAR-25-2011
2 (B)	Panel mounting加C0.1與增加PCB mounting		MAY-18-2011
3 (C)	4.05尺寸加註公差 +0.4/-0.1		AUG-16-2011
4 (D)		增加LED規範	OCT-17-2011
5 (E-1)	依據ECN GC14040402設變, PBL底座與上蓋組裝改為超音波熔接結構		APR-21-2014
5 (E-2)	LED SPEC改為參閱規格書文字說明		APR-21-2014
6 (F)		增加11.7尺寸標示	OCT-15-2015
7 (G)	提升產品結合強度, 底座原超音波熔接更新結構為四卡扣		AUG-02-2017

SCALE (比例) : 3 : 2

TOLERANCE (公差) :
0.00 mm ± 0.25mm
0.0 mm ± 0.40mm
ANGULAR : ± 5°
FILE NAME : PBL0002

德利威電子股份有限公司 DAILYWELL ELECTRONICS CO., LTD.					
TITLE 圖名	Pushbutton Switches			SIZE 圖紙	A4
DWG NO. 圖號	PBL-03			UNIT 單位	mm
REV. 版本	H	DATE 日期	NOV - 11 - 2010	SHEET 張數	1 of 1
CHECKED BY 審核	陳燈財		DRAWN BY 製圖	IRENE	