
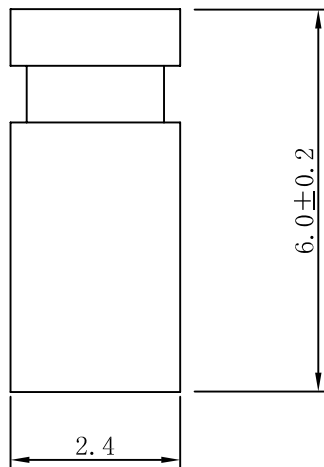
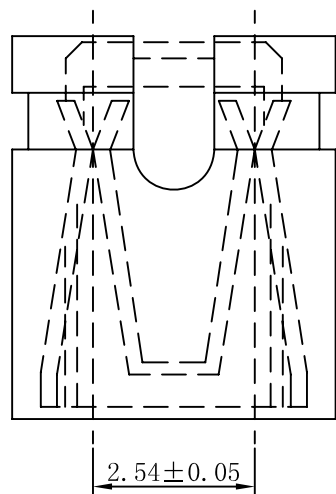


环保物料

TEL:0769-82001899

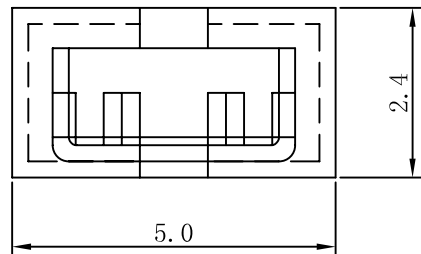

SPECIFICATION

Current Rating :3AMP
 Insulator Resistance :1000MΩ Min.
 Contact Resistance :20mΩ Max.
 Dielectric With Standing :AC 500V/min. R. M. S.
 Operating Temperature :-40℃ To + 105℃
 Contact Material :Brass .
 Insulator Material :PBT, UL-94V-0
 Plating :Nickel

A
B
C
D
E
F
G

A
B
C
D
E
F
G

TOLERANCE UNLESS OTHERWISE

X.	±0.30	X°	±5°
.X	±0.20	.X°	±2°
.XX	±0.08	.XX°	±1°
.XXX	±0.03	.XXX°	±0.5°

DRAWN

CK tan

CHKD

APPD

VIEW



XFCN兴飞连接器有限公司
 CONNECTORS XFCN CONNECTORS CO., LTD.

PRODUCT NAME

JUMP 2.54 H:6.0 常開半金

PART. NO.

F254D-02-PT-B

SHEET

1/1

DATE

2010. 4. 12

UNITS

mm

SCALE

1:1

DWG NO.

009

AO
VER

MODIFICATION

DRAW

DATE

1 2 3 4 5 6 7 8 9 10