


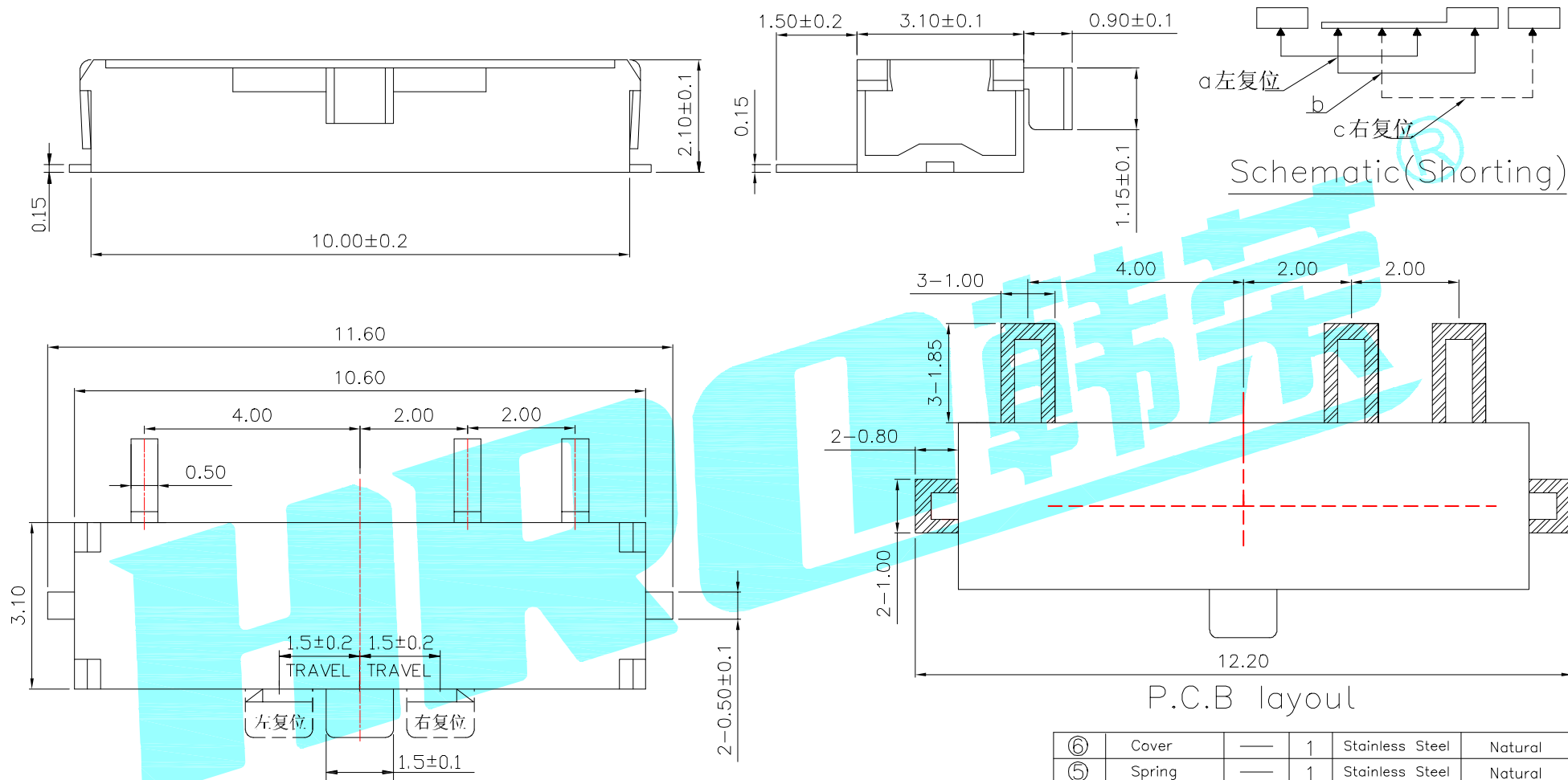

Typical Specifications
1. Rating : 12V 0.1A DC
2. Operating force: 100 ± 30 gf
4. Operating Life : 10,000 cycles

⑥	Cover	——	1	Stainless Steel	Natural	——
⑤	Spring	——	1	Stainless Steel	Natural	——
④	Contact Clip	——	1	C5210	Ag Clad	——
③	Knob	——	1	PA	DarkCyan	——
②	Base	——	1	LCP	Black	——
①	Terminal	——	3	Brass	Ag Plated	——
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK
APPROVALS			DATE	HRO韩荣® ELECTRONICS CO.,LTD		
DRAWN	JIANKUN.LU	2015.5.25				
CHECKED				TITLE:	SLIDE SWITCHS	
APPROVALS				PART NO.	K3-1392M-G1	
TOLERANCES ARE		30~以上	±0.30	ANGLE	UNIT: mm	SCALE: 1:1
		10~30	±0.20			
		5~10	±0.15			
		~ 5	±0.10			
		±2°	DRAWING NO.	——	PROJ: 	
					SHEET 1 OF 1	

	A		NEW			
ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.