
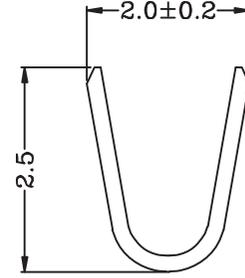


环保物料


TEL: 0769-82001899

SPECIFICATIONS


Voltage rating: 250V AC, DC
 Current rating: 3A, AC, DC
 Withstanding Voltage: 1000V AC/minute
 Insulation resistance: 1000M Ω min
 Temperature range: -25 °C ~ +85 °C
 Contact resistance: 20m Ω max
 Applicable wire: AWG#24-#30
 Material: Phosphor Bronze
 Finish: Tin Plated
 Part No.: T2020PS-2

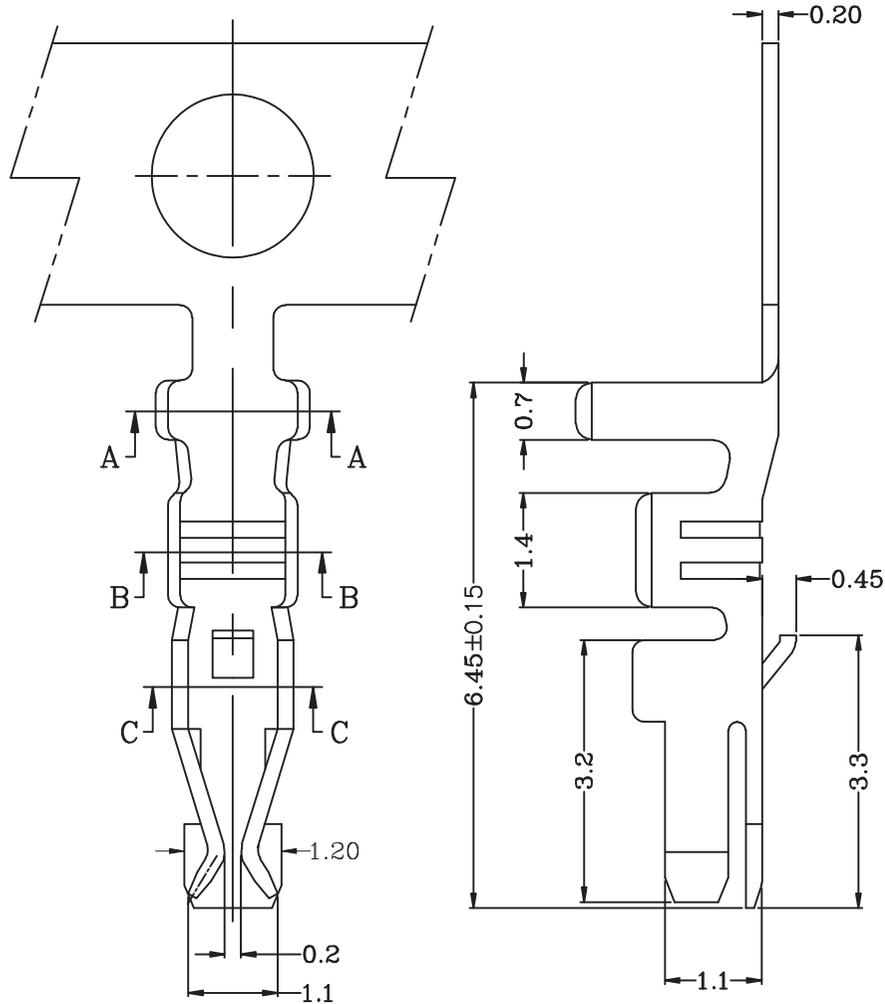

Section A-A

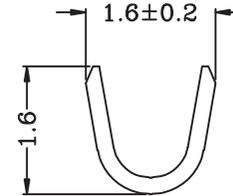

Section B-B

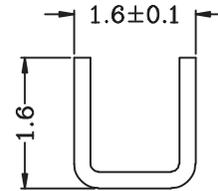

Section C-C

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	XFCN 兴飞连接器有限公司 CONNECTORS XFCN CONNECTORS CO., LTD.		SHEET	1/1
				X.	±0.30	X°	±5°			CHKD	DATE
				.X	±0.20	.X°	±2°	APPD	PRODUCT NAME	2.00mm Crimp Style Connectors	
				.XX	±0.08	.XX°	±1°	VIEW	PART. NO.	T2020PS-2	
				.XXX	±0.03	.XXX°	±0.5°			SCALE	1:1
										UNITS	mm
										SCALE	1:1
										DWG. NO.	009

A0
VER

MODIFICATION

DRAW

DATE