


### 技术参数 SPECIFICATIONS

- 适用线规 (Applicable wires) : AWG24#~16#
- 温度范围 (Temperature range) : -25 °C~85 °C
- 额定电压 (Voltage rating) : 300V.Ac/Dc
- 额定电流 (Current rating) : 12A max
- 接触电阻 (Contact resistance) :  $\leq 0.01\Omega$
- 绝缘电阻 (Insulation resistance) :  $\geq 1000M\Omega$
- 耐压 (Withstand voltage) : 2000V.Ac/1min
- 材料 (Material) :
  - 壳体 (Housing) : 尼龙 (PA66) UL94V-2(0)
  - 端子 (Terminal) : 磷青铜 (Phos.bronze Tin/plated)  
黄铜 (B rass Tin/plated)

 
### .110/.187\* 端子 TERMINAL

| 型号 Type    |              | 适用线规<br>Applicable wires |       | 材料<br>Material     | 尺寸Dimensions (mm) |      |     |                   | 示图<br>Sample | 数量<br>Quantity |
|------------|--------------|--------------------------|-------|--------------------|-------------------|------|-----|-------------------|--------------|----------------|
|            |              | mm'                      | AWG#  |                    | W                 | L    | E   | 材料厚度<br>Thickness |              |                |
| HX480N-01T | ST0-01T-187N | 0.2~0.5                  | 24~20 | 黄铜<br>Brass        | 5.7               | 15.0 | 6.5 | 0.35              | A            | 10000PCS/卷     |
| HX480N-41T | ST0-41T-187N | 0.5~1.25                 | 20~16 |                    | 5.7               | 15.0 | 6.5 | 0.35              |              | 10000PCS/卷     |
| HX480N-61T | ST0-61T-187N | (UL1015) 20+18           |       |                    | 5.7               | 15.0 | 6.5 | 0.35              |              | 10000PCS/卷     |
| HX28010-PT | 730629-3     | 0.5~1.42                 | 20~16 | 磷青铜<br>Phos.bronze | 3.8               | 15.6 | 7.6 | 0.25              | B            | 15000PCS/卷     |

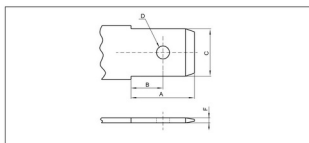


| 型号<br>Type | 尺寸Dimensions (mm) |     |     |            |     |
|------------|-------------------|-----|-----|------------|-----|
|            | A                 | B   | C   | D          | F   |
| .187*      | 7.0               | 3.6 | 4.8 | $\phi 1.5$ | 0.5 |

### HX480N-T




(A)

### HX480-187ZH

 


### HX28010-PT

 


(B)

### HX28010-3P (610539)

 

### HX28015-3P

 

### HX28020-3P (610815)

