



技术参数 SPECIFICATIONS

- 适用线规 (Applicable wires) : AWG24#~14#
- 温度范围 (Temperature range) : -25℃~85℃
- 额定电压 (Voltage rating) : 300V.Ac/Dc
- 额定电流 (Current rating) : 15A max
- 接触电阻 (Contact resistance) : $\leq 0.01\Omega$
- 绝缘电阻 (Insulation resistance) : $\geq 1000M\Omega$
- 耐压 (Withstand voltage) : 2000V.Ac/1min
- 材料 (Material) :
 - 壳体 (Housing) : 尼龙 (PA66) UL94V-0
 - 端子 (Terminal) : 黄铜 (Brass Tin/plated)

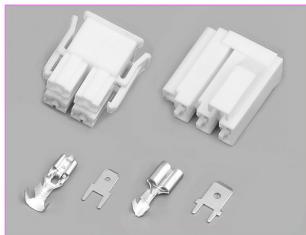

.187"/.250" 端子 TERMINAL

型号 Type	适用线规 Applicable wires	mm ²	AWG#	材料 Material	尺寸 Dimensions (mm)				示例 Sample	数量 Quantity
					W	L	E	材料厚度 Thickness		
HX4.8S-01T	730567-3	0.22~0.5	24~20		5.6	19.3	5.1	0.3	A	10000PCS/包
HX4.8S-21T	730568-3	0.55~1.28	20~16	黄铜 Brass	5.6	19.3	5.1	0.3		8000PCS/包
HX4.8S-41T	730569-3	0.76~2.09	18~14		5.6	19.3	5.1	0.3		6000PCS/包
HX6.3Z-21PT	35725-4210	0.55~1.28	20~16	黄铜 Brass	7.5	18.5	7.7	0.4	B	

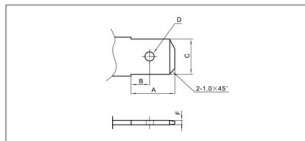

型号 Type	尺寸 Dimensions (mm)				
	A	B	C	D	F
.187"	7.0	3.6	4.8	φ1.5	0.5
.250"	8.3	3.8	6.35	φ2.0	0.8

