
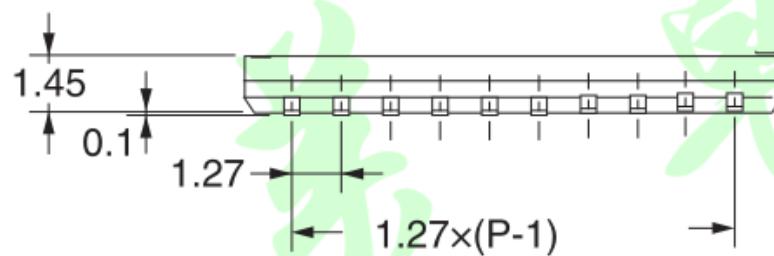
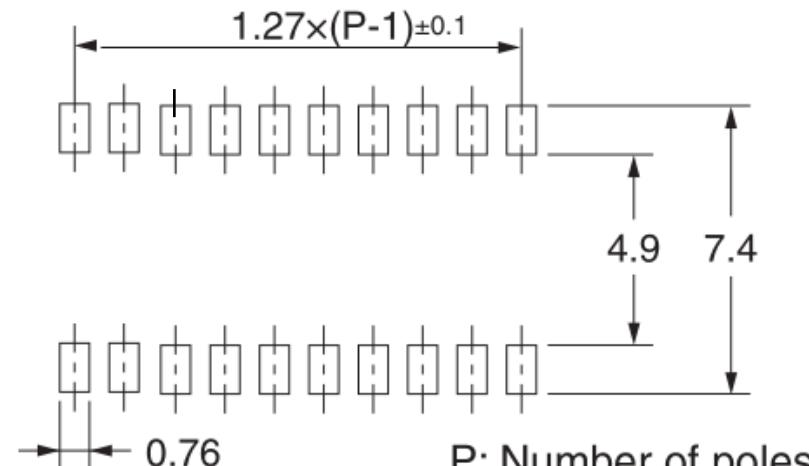



Rating (resistive load)	25 mA at 24 VDC 10 µA (minimum current) at 3.5 VDC
Ambient operating temperature	-20 to +70°C at 60% max. (with no icing or condensation)
Ambient operating humidity	35% to 95% (at +5 to +35°C)
Insulation resistance	100 MΩ min. (at 250 VDC with insulation tester)
Contact resistance (initial value)	200 mΩ max.
Dielectric strength	Between terminals 300 VAC for 1 min
Vibration resistanc	Malfunction 10 to 55 Hz, 1.5-mm double amplitude
Shock resistanc	Malfunction 300 m/s ² min.
Durabilit	Electrical 1,000 operations min.
Washing	Standard models: Not possible, Models with seal tape: Possible
Degree of protection	IEC IP40
Operating force	0.29 to 4.9 N {30 to 500 gf}

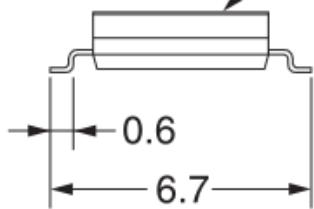

P: Pole numbers

Seal tape
(t=0.05)

P: Number of poles

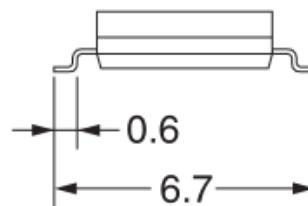

>0.5~2	± 0.05	± 0.10	± 0.15	第一视角 	设计 Jack Jin	图面 单位	A4 MM	东莞市美韩电子科技有限公司		
>2~5	± 0.15	± 0.20	± 0.25		审核 Jacky Zhong	比例	1 : 1	DWG NO.	型号: UK-DSHP04TSGER-S	Dongguan Usakro Electronic Technology Co., Ltd.
>5~10	± 0.25	± 0.28	± 0.30		批准 Tony Meng	重量				SIZE A4
角度 ANGLE			± 0.5°		页码	1/1				VER R
未注尺寸公差(mm)					版次	A/0	1 of 1	PART NO.	规格: 1.27*6.7 10PIN贴片	