

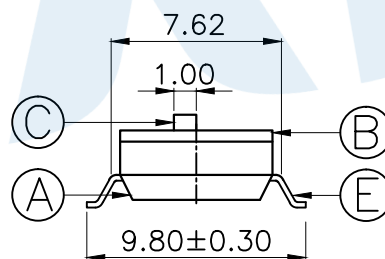
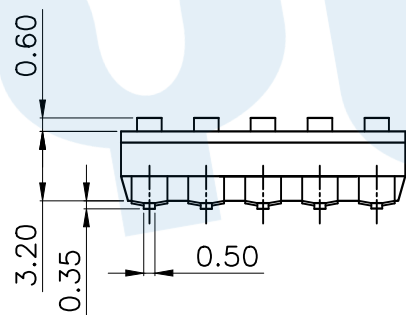
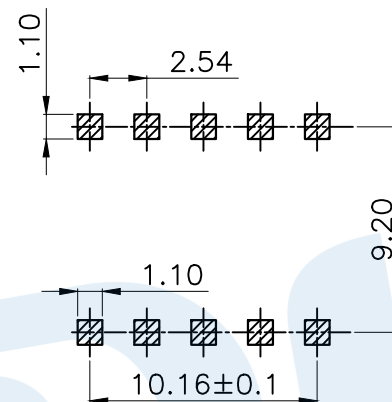
 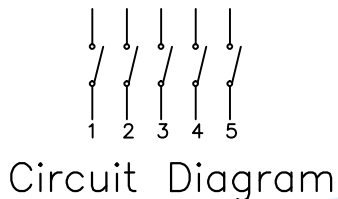


RoHS

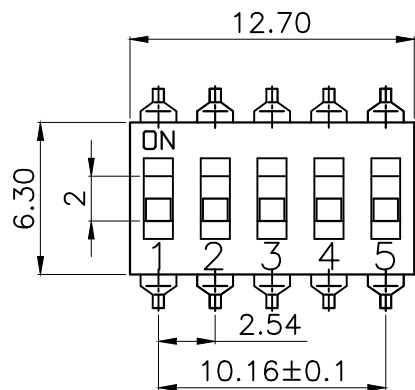

凸柄 Convex handle



短柄 Short handle

NOTE:

- 1.Rating: 24V 25mA DC
- 2.Insulation Resistance: $\geq 100 \text{ M}\Omega$
- 3.Withstand voltage:AC 500V 1Minute
- 4.Operating Force Range: 500gf Max
- 5.Mechanical Life:3,000 Cycles

| Number of digits(位数) | 1P | 2P | 3P | 4P | 5P | 6P | 7P | 8P | 9P | 10P | 12P |
|------------------------------------|--------|--------|--------|--------|--------|--------|--------|--------|--------|--------|--------|
| Cover/black 凸柄 Convex handle | TO-01 | TO-02 | TO-03 | TO-04 | TO-05 | TO-06 | TO-07 | TO-08 | TO-09 | TO-10 | TO-12 |
| 盖子/黑色 短柄 Short handle | TO-01D | TO-02D | TO-03D | TO-04D | TO-05D | TO-06D | TO-07D | TO-08D | TO-09D | TO-10D | TO-12D |

| Ⓔ | Terminal | | 10 | Brass | Gold plating |
|-----|----------|--------|-----|------------------|--------------|
| Ⓕ | Shrapnel | | 5 | Beryllium copper | Gold plating |
| Ⓒ | Handle | | 5 | PA46 | White |
| Ⓑ | Cover | | 1 | PPS | Black |
| Ⓐ | Base | | 1 | PPS | Black |
| NO. | Name | Number | Qty | Materil | Remarks |

YUANDI® Yuandi Electronics Co.,Ltd

| | | | |
|----------|------|-------|------------|
| design | date | name | DIP SWITCH |
| Review | date | model | TO-05 |
| Approved | date | | |

Drawing number: Proportion 1:1 unit mm gage number A4

modify Review Approved Tolerance not specified