

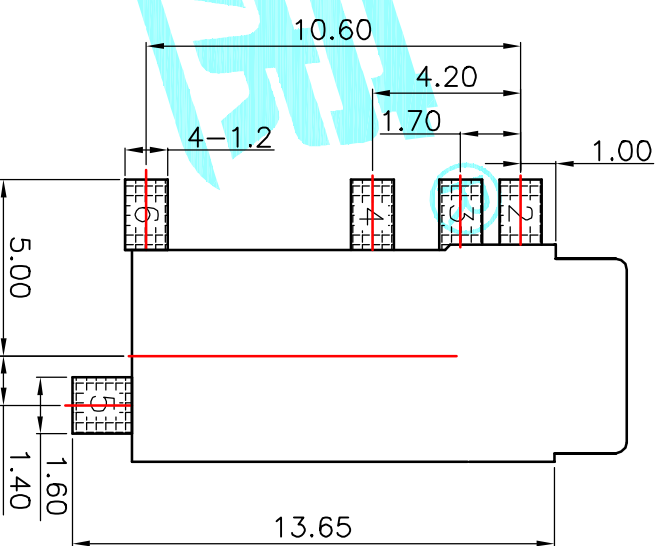
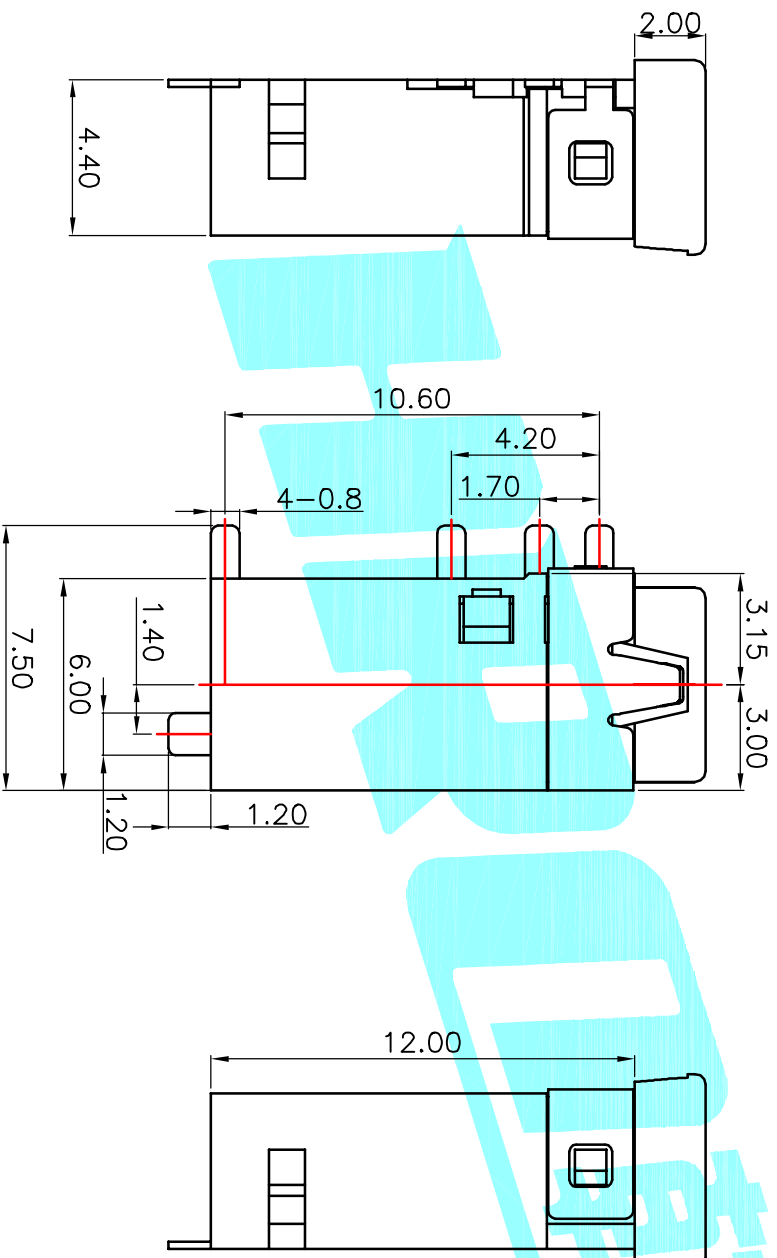


ROHS

Rating:0.5A 30V DC
Contact Resistance:100 mΩ Max.
Operating temperature:−20℃~70℃
Operating force:3–20N
Operating Life:5,000cycles

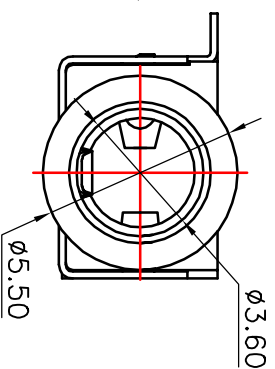

P.C.B LAYOUT TOP VIEW

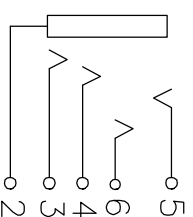

SCHEMATIC

[illegible]