



港版-B7000

原装高品质 点钻胶水 SPOT DRILL GLUE

易点胶、不伤手
固化效果强，无腐蚀

Easy gel, no hand injury
Strong curing effect, no corrosion

透明色胶体
Transparent colloid



COMMODITY PARAMETERS

———商品参数



名称：点钻胶水
型号：B7000
容量：50ML
颜色：透明胶体
固含量：28-35%
固化后硬度：80-95A
表面固化时间：3-5MINS
完全固化时间：24-48 HR
储存温度：10-28℃

Name: Drilling glue
Model: B7000
Capacity: 50ML
Color: transparent colloid
Solid content: 28-35%
Hardness after curing: 80-95A
Surface curing time: 3-5 min
Complete cure time: 24-48 HR
Storage temperature: 10-28 C



MECHANIC THE WORLD

技艺百年 匠心制作


结合工艺百年,用心去专研;采用良心的品质,精工制成
如今,维修佬已经成长为由全球1000多名工程师组成的技术
创新公司,其产品也在逾132个不同国家的市场取得了成功
但是,我们仍在不停进步而这一切的核心,是我们不断壮大的
工程师及科学家团队与他们源源不断的创意

严格产品标准

维修佬拥有自己专业的生产团队
您使用的胶水都经过层层把关,品质有保障

Repair man has his own professional production team
The glue you use is checked layer by layer for guaranteed quality



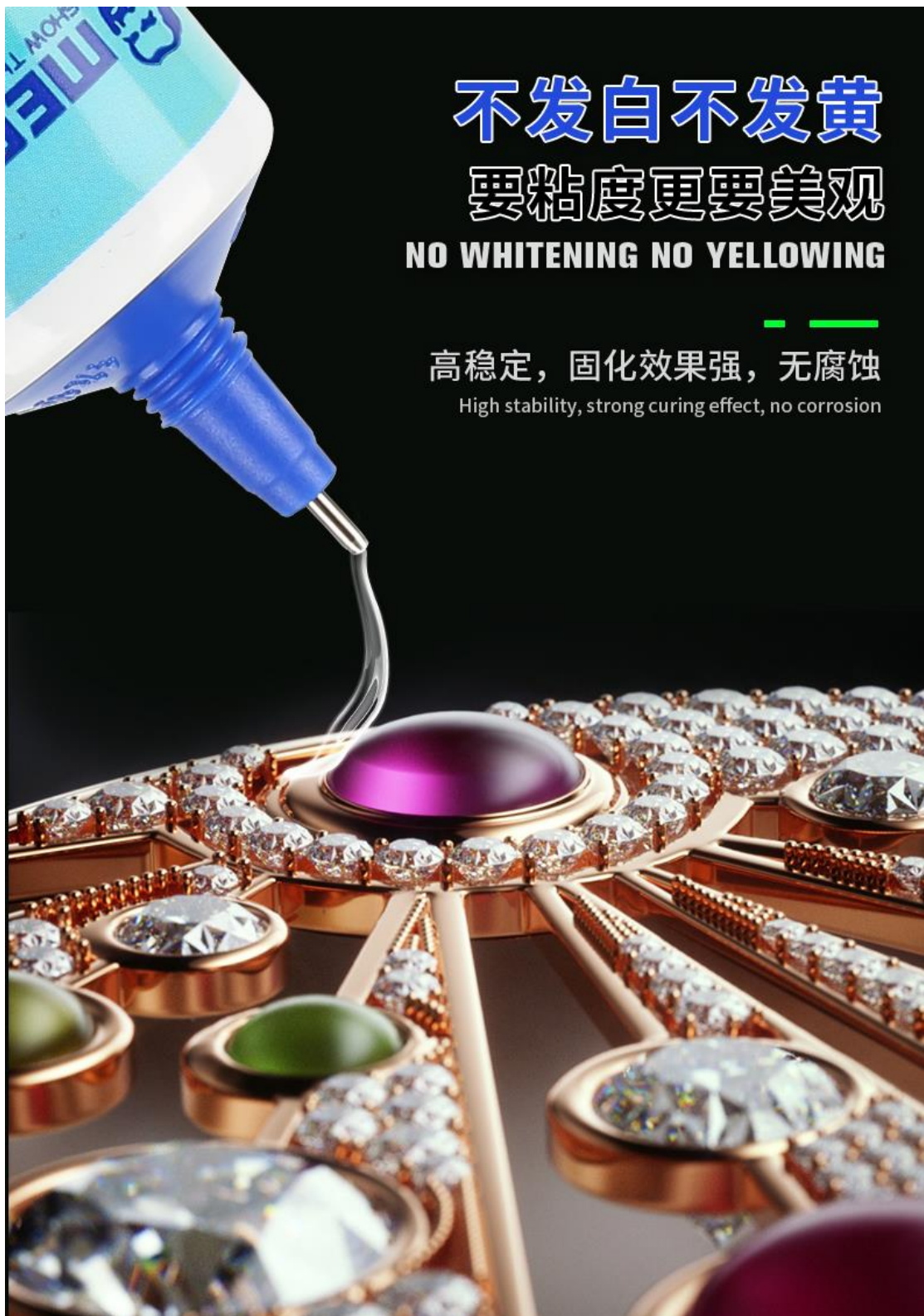

不发白不发黄

要粘度更要美观

NO WHITENING NO YELLOWING

高稳定，固化效果强，无腐蚀


High stability, strong curing effect, no corrosion

NEEDLE-TYPE GLUE DELIVERY

方便耐用 针式出胶便捷不堵嘴

准确点胶,软胶体
点对点结合不浪费每一滴胶

Accurate dispensing, soft colloid
Point-to-point binding does not waste every drop of glue

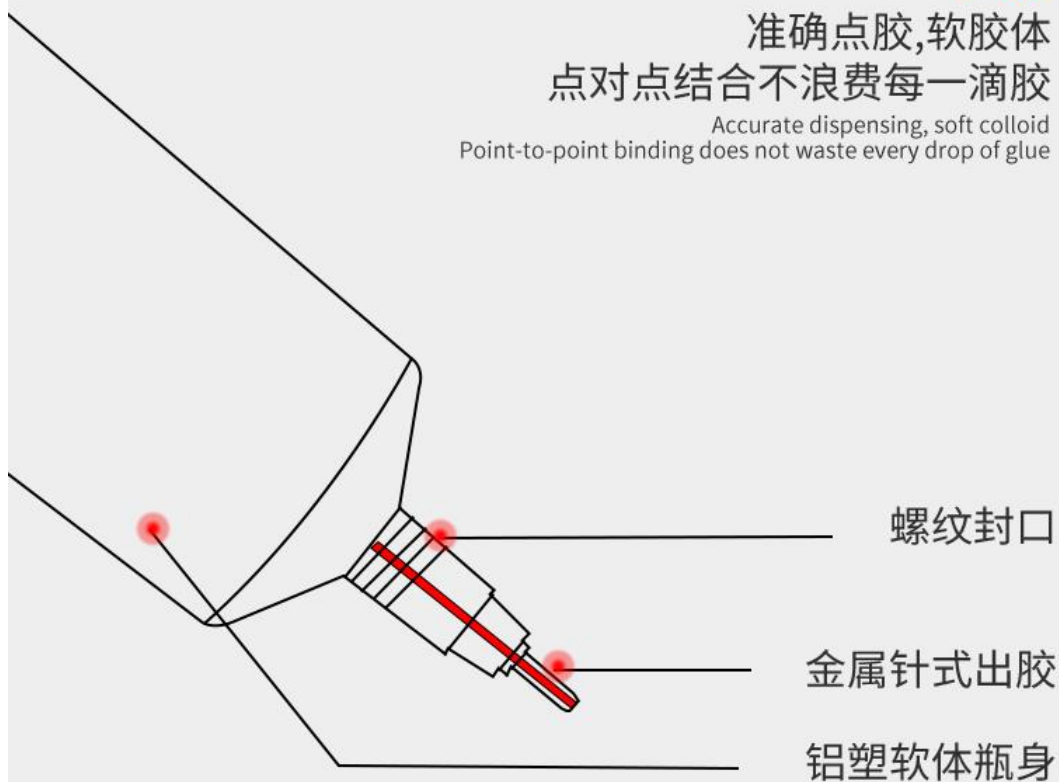

专利号
201720000977.2

高强力 强防水

手机为电子产品
本身不具有防水功能
粘接防水只针对粘接位不易渗水

环保
材料

高透明

不伤手



NO HAND INJURY

针头出胶快捷
胶液不伤手

液体清澈透明，无刺激气味

The liquid is clear and transparent with no irritating odor.

