





HSF

NOTES:
 Current Rating: 1AMP
 Contact Resistance: 35mΩ max
 Withstand Voltage: 500V AC/DC
 Insulation Resistance: 1000MΩ min
 Operation Temperature: -55℃ to +105℃

Contact Material: Phosphor Bronze
 Contact plating: Au or Sn over Ni
 Shell Material: SPCC, t=0.50mm
 Housing Material: PBT+30%GF(UL94V-0)
 Cover Material: LCP+30%GF(UL94V-0)

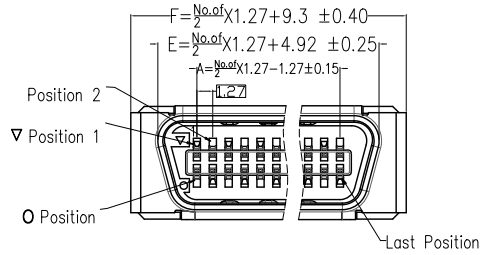

| PART NO. | PIN | A | E | F | G |
|--------------------|------|-------|-------|-------|-------|
| 6320M-014SSXXMNA01 | 14P | 7.62 | 13.81 | 18.19 | 17.14 |
| 6320M-020SSXXMNA01 | 20P | 11.43 | 17.62 | 22.00 | 20.95 |
| 6320M-026SSXXMNA01 | 26P | 15.24 | 21.43 | 25.81 | 24.76 |
| 6320M-036SSXXMNA01 | 36P | 21.59 | 27.78 | 32.16 | 31.11 |
| 6320M-040SSXXMNA01 | 40P | 24.13 | 30.32 | 34.70 | 33.65 |
| 6320M-050SSXXMNA01 | 50P | 30.48 | 36.67 | 41.05 | 40.00 |
| 6320M-068SSXXMNA01 | 68P | 41.91 | 48.10 | 52.48 | 51.43 |
| 6320M-080SSXXMNA01 | 80P | 49.53 | 55.72 | 60.10 | 59.05 |
| 6320M-100SSXXMNA01 | 100P | 62.23 | 68.42 | 72.80 | 71.75 |

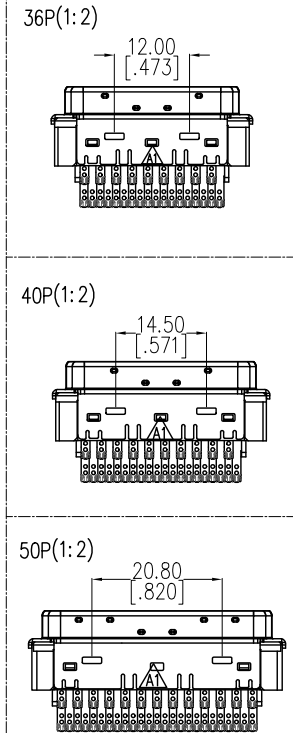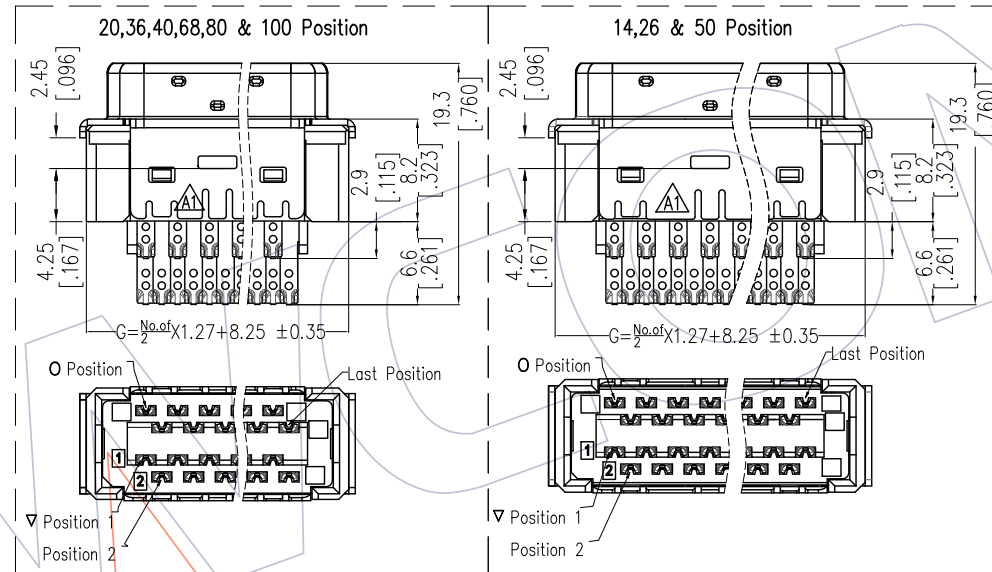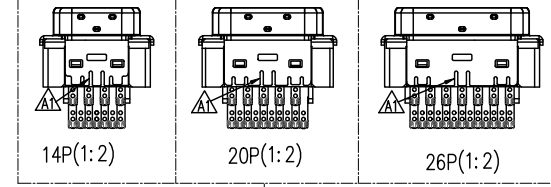


Ordering Information

6320M- XXX S S XX M N A 01

No. of Pins: 014=14P
 020=20P
 026=26P
 036=36P
 040=40P
 050=50P
 068=68P
 080=80P
 100=100P

Contact Plated:
 S1=Sel. 3u"Gold /Tin
 S2=Sel. 5u"Gold /Tin
 S3=Sel. 10u"Gold /Tin
 S4=Sel. 15u"Gold /Tin
 S5=Sel. 30u"Gold /Tin

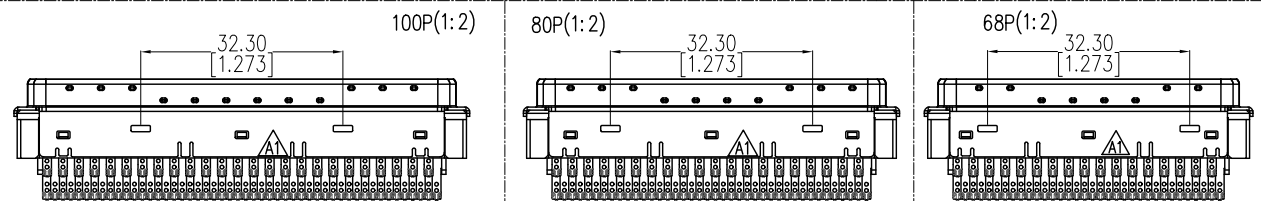

| REV | DATE | MODIFICATION DESCRIPTION | CHANGE | OPERATION | DRAW | DATE | SCALE | FIT | PART NO. |
|-----|------------|--------------------------|--------|-----------------------|---------|------------|-------|--------------|--|
| A2 | 2020/08/25 | CHAMFER | XSR | x.x ±0.40 | XSR | 2020/08/25 | UNIT | mm | 6320M-XXXSSXXMNA01 |
| A1 | 2019/09/20 | MODIFY | XSR | x.xx ±0.25 | CHECK | DATE | SIZE | A4 | |
| A0 | 2019/06/06 | NEW | --- | x.xxx ±0.15 | APPROVE | DATE | SHEET | 1/1 | TITLE: 1.27mm MDR SCSI Male (Soldering Type) |
| REV | DATE | MODIFICATION DESCRIPTION | CHANGE | Angle DIM TOL ± 3° | APPROVE | DATE | PROJ. | Customer NO. | |

WCON

Http: www.wcon.com

WCON-Dongguan Tel: +86 769 85358920
 WCON-Kunshan Tel: +86 512 57468408
 Fax: +86 769 85358915
 Fax: +86 512 57468468
 E-mail: sales@wcon.com
 E-mail: salesks@wcon.com