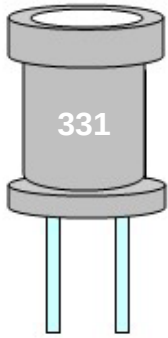
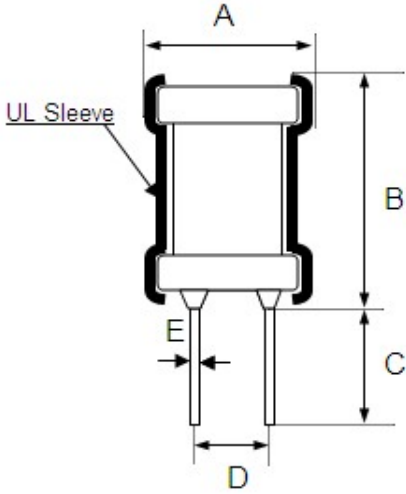


產品製作規格書

產品料號	303-49004	VER:0	產品名稱:	RL0608N/18-112-331K		
圖面說明(單位:mm)			使用材料	注意事項		
  			A	DRW6×8FS0	SR60(開槽接腳)	
			B	Ø0.18mm(2UEW)	原色	
			C	UL Ø6×10 mm印"331"		
			D			
			E			
			F			
			G			
			尺寸 (mm)			
			A	6.7±1.0	E	Ø0.65 ± 0.1
			B	9.2±1.0	F	
C	3.4±0.5	G				
D	3.0±1.0	H				
測試儀器 (首行為承認儀器)	L (uH)	DCR Ω(Max)	IDC A(Max)	測試條件		
TH2816B	330.0±10%	1.7	0.50	200KHz,0.25V		
客戶編碼	產品料號	送樣編號	修改項目	修改參數		
	303-49004	M15-06085				
包裝方式						
A	300	PCS/袋	D			
B	4	袋/盒	E			
C	10	盒/箱	F			
作業內容			修改記錄			
1.用DRW6×8FS0的無鉛CORE(B=3.0mm;F=4.2mm;P=3.0)生產.			時間	料號	修改內容	
2.用2UEW Ø0.18mm的原色銅線,繞112Ts(REF).			1			
3.用Ø6×10 mm印白色"331"的套管.			2			
4.採用繞線新制程.			3			
5.產品以無鉛制程制作.			4			
			5			
			6			
			7			
注意事項			8			
1.以感值為主,圈數為輔.			備 注			
2..用同等功能儀器測試.			A	1PCS產品單重:1.051g.		
3.產品L值按100%全測, DCR值按10%抽測.			B			
			C			
			D			
核準:_____			製表: 張小萍			
審核:_____			發文日期: 2015.7.27			