




◆寸法図／DIMENSIONS

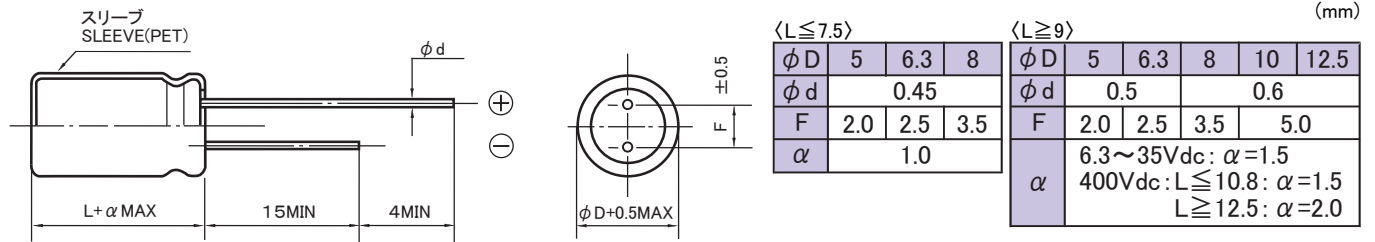

◆標準品一覧表／STANDARD SIZE

Rated Ripple Current (mA r.m.s./105°C, 100kHz), Impedance ( $\Omega$  MAX/20°C, 100kHz)

定格電圧 Rated Voltage (Vdc)	静電容量 Capacitance ( $\mu F$ )	外形寸法 Size $\phi D \times L$ (mm)	定格リップル 電流 Rated Ripple Current	インピーダンス Impedance
6.3	82	5×7	510	0.25
	220	5×11	800	0.14
		6.3×7	720	0.13
	470	6.3×11	1140	0.067
		8×7.5	1080	0.065
	680	8×9	1360	0.049
	820	8×10.8	1600	0.042
	1000	8×16	2010	0.027
10×9		1540	0.036	
		1970	0.025	
8	75	5×7	510	0.25
	200	5×11	800	0.14
		6.3×7	720	0.13
	390	8×7.5	1080	0.065
	430	6.3×11	1140	0.067
	620	8×9	1360	0.049
	750	8×10.8	1600	0.042
	910	8×16	2010	0.027
		10×9	1540	0.036
	1100	10×12.5	1970	0.025
10	68	5×7	510	0.25
	180	5×11	800	0.14
		6.3×7	720	0.13
	330	8×7.5	1080	0.065
	390	6.3×11	1140	0.067
	560	8×9	1360	0.049
	680	8×10.8	1600	0.042
		8×16	2010	0.027
	820	10×9	1540	0.036
10×12.5		1970	0.025	

定格電圧 Rated Voltage (Vdc)	静電容量 Capacitance ( $\mu F$ )	外形寸法 Size $\phi D \times L$ (mm)	定格リップル 電流 Rated Ripple Current	インピーダンス Impedance
16	390	8×9	1360	0.049
	470	8×10.8	1600	0.042
	560	8×16	2010	0.027
		10×9	1540	0.036
	680	10×12.5	1970	0.025
	1000	10×16	2480	0.019
25	220	8×9	1360	0.049
	270	8×10.8	1600	0.042
	390	8×16	2010	0.027
		10×9	1540	0.036
	470	10×12.5	1970	0.025
	680	10×16	2480	0.019
35	150	8×9	1360	0.049
	180	8×10.8	1600	0.042
	220	8×16	2010	0.027
		10×9	1540	0.036
	270	10×12.5	1970	0.025
	390	10×16	2480	0.019

Rated Ripple Current (mA r.m.s./105°C, 120Hz)

定格電圧 Rated Voltage (Vdc)	静電容量 Capacitance ( $\mu F$ )	外形寸法 Size $\phi D \times L$ (mm)	定格リップル 電流 Rated Ripple Current
400	4.7	8×9	50
	6.8	8×10.8	70
	7.5	8×10.8	75
	8.2	8×16	85
		10×9	
	10	8×16	90
		10×12.5	100
	12	8×20	120
		10×12.5	110
	15	8×20	130
		10×16	150
	18	10×16	150
	22	12.5×16	180
24	12.5×16	190	