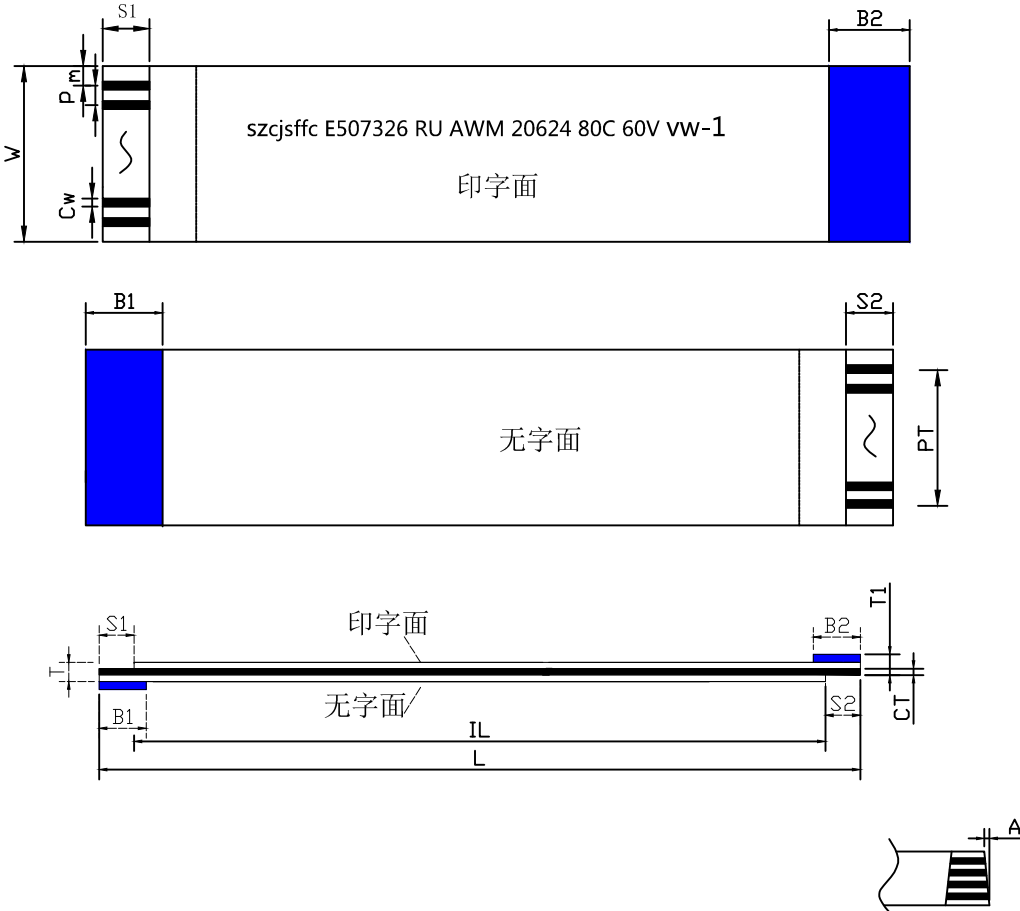


|                           |       |    |                                                                             |     |                                                                                      |
|---------------------------|-------|----|-----------------------------------------------------------------------------|-----|--------------------------------------------------------------------------------------|
| CUSTOMER(客户):             |       |    | Customer Part NO. (客户部品号):                                                  |     |                                                                                      |
|                           |       |    | Part Descripon(部品规格):                                                       |     |                                                                                      |
| Item                      | 项目    |    | Specification                                                               | 规格值 |                                                                                      |
| NO. of conductors         | 导体芯数  | N  | 6P-96P                                                                      |     |  |
| Pitch                     | 间距    | P  | 0.5±0.05                                                                    |     |                                                                                      |
| Total Pitch               | 全间距   | PT | 2.5-47.5±0.08                                                               |     |                                                                                      |
| Total Length              | 总长度   | L  | 25-20000±2                                                                  |     |                                                                                      |
| Insulation Length         | 绝缘长度  | IL | 25-20000±2                                                                  |     |                                                                                      |
| Margin Width              | 边缘宽度  | M  | 0.5±0.08                                                                    |     |                                                                                      |
| Total Width               | 总宽度   | W  | 3.5-48.5±0.08                                                               |     |                                                                                      |
| Strip Length              | 线口长度  | S1 | 1.5-5±0.5                                                                   |     |                                                                                      |
| Strip Length              | 线口长度  | S2 | 1.5-5±0.5                                                                   |     |                                                                                      |
| Reinforeing tape length   | 补强板长度 | B1 | 2.5-30±2                                                                    |     |                                                                                      |
| Reinforeing tape length   | 补强板长度 | B2 | 2.5-30±2                                                                    |     |                                                                                      |
| Slanting                  | 线口倾斜度 | A  | ≤0.3                                                                        |     |                                                                                      |
| Over lap                  | 冲孔    |    | /                                                                           |     |                                                                                      |
| Terminal thickness        | 插入厚度  | t1 | 0.3±0.02                                                                    |     |                                                                                      |
| Thickness insulation      | 线身厚度  | t  | 0.12±0.02                                                                   |     |                                                                                      |
| Conductor thickness       | 导体厚度  | Ct | 0.035±0.01                                                                  |     |                                                                                      |
| Conductor width           | 导体宽度  | Cw | 0.3±0.03                                                                    |     |                                                                                      |
| Supporting Tapc Color     | 补强板颜色 |    | Storage condition(储存条件):Recommended(推荐)                                     |     |                                                                                      |
| PET(Supporing Tapc Color) | 补强板规格 |    | Temp:15° C~25° C(温度15° C~25° C)Humidity:30~60RH%(湿度30~60RH%)                |     |                                                                                      |
| PET(Insulation)           | 绝缘胶规格 |    | Drawing Not To Scale<br>Hidden Lines Not Shown<br>图规不能以其线材比便来<br>衡量,隐藏线不显示。 |     |                                                                                      |
| PET(Insulation)           | 绝缘胶规格 |    | Unit(单位):mm                                                                 |     |                                                                                      |
| Rev                       | 版本    |    | Unit(单位):mm                                                                 |     |                                                                                      |