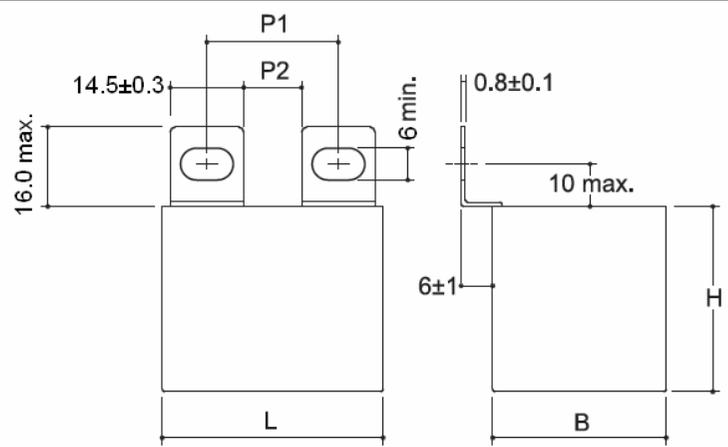


SPECIFICATION FOR APPROVAL

CUSTOMER	立创	SHAPE	
PART NAME	IGBT Snubber Capacitor	Marking	
TYPE	Type-APB		
ISSUED NO	E170815-01	Case color=White	
ISSUED DATE	Aug.15.2017	Epoxy resin color=White	

CUSTOMER PART NO.	CAP. (μF)	CAP.TOL (±%)	RV (VDC)	DFMax 1KHz	ESR 100KHz	dV/dt (V/μs)	Ipk (A)	100 kHz	IR(MΩ)	TV	DIMENSION unit: mm					Hongfarad PART NO.
								70 °C(Arms)	100V60S	Vdc 10s	L±1	H±1	B±1	P1±1	P2±1	
C2913430	2.2	5	1200V	0.1%	4.1	500	1,100	23.5	45,500	1,920	57.5	45.0	30.0	25.0	10.5	HAPB1K2W22J0M6

FEATURES:
 THE Type-APB are constructed with special extended double metallized polyester electrodes with metallized polypropylene dielectric internal series connection , Lug terminal , encapsulated in UL 94V-0 plastic case with epoxy resin sealed.

APPLICATIONS:
 They are ideal for Snubber, energy conversion and control in power semiconductor circuits, IGBT modules protection and SMPS protection circuits , high voltage , high current and high pulse applications.

东莞市弘源电子有限公司 TECHNICAL DEPARTMENT		
APPROVE	CHECK	DESIGN
Amy Leng 2017.08.15		Shencheng 2017.08.15