


U221-04XN-4 BZ57- F1

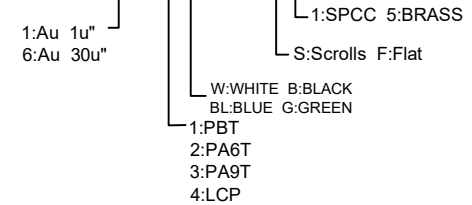

备注 Notes:

- 电气性能 Electrical performance:
  - 额定电流 Respect for current: 1.5A MIN 250V AC.
  - 接触电阻 Contact resistance: 50 mΩ.MAX
  - 绝缘电阻 Resistance resistance: 1000 MΩ MINI 300V/AC
  - 电介质耐电压 Dielectric withstand voltage: 500V AC 1M
- 环境性能 Environmental performance
  - 操作温度 Operating temperature -40°C to 85°C
- 机械特性 Mechanical characteristics
  - USB插拔测试 USB plugging test: plugging and unplugging for 200 cycles, plugging and unplugging for 1500 cycles, Function is not impaired.
  - USB插拔力测试 USB plug-in force test: after the plug-in test 5 times, the plug-in force is ≤35N, Withdrawal force ≥10N. Pull-out force ≥ 8N after 1500 times of plug-in test.
  - Salt spray 24H, salt spray collection volume 1.5mL, temperature 35°, salt spray 47%.
  - The contact PIN needle and the holding force of the rubber core are ≥0.8kg.
- 耐高温 High temperature: wave soldering (left and right 220°±5°), no There are undesirable bubbles such as swelling and melting, and the warping deformation is within the range.
- Product solder test, the area of sticking tin reaches more than 95%;
- Meet the requirements of USB 2.0 Association standards.
- Those marked with "\*" are key inspections.

					ANGLAR	±5°	DSND		DATE		SCALE: N/A	MODEL TYPE: USB 2.0
					L ≤ 4	±0.2	DWN		DATE		VIEW:	PART NO.:
					4 < L ≤ 16	±0.3	CHKD		DATE		UNIT: mm/in	DWG NO.:
					16 < L ≤ 63	±0.4	APPD		DATE		SIZE: A4	U221-04XN-4BZ57-F1
					L > 63	±0.5						UNSPECIFIED TOLERANCES
REVISIONS					XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT	SHEET	REVISION		
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn								1.0g	1/1	A0		