

CONNECTORS

Operation: SMT/沉板卧式 MINI-USB 连接器(5PIN)



LTEM NO.: CZ-519 (Series)

(L9.0×W7.7×H3.9 DC-CONNECTORS)



表面贴装 SMT

侧向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

适合环保 RoHS


Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical	Contact Rating	25mA, 24V DC	
	Initial Contact Resistance	50mΩ max.	
Properties	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
Storage temp.		-35℃~+75℃(Operating Temp:)	
Operating Force		IF:35N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration

No.	NAME	Description
① A	基座	LCP (Gray)耐高温塑胶 UL94V-0
② B	动态端子	磷铜 C5191 [锡基镀金/S1]
③ C	外壳	黄铜 C2680/SPCC [镀锡50u" min]

Unit:mm

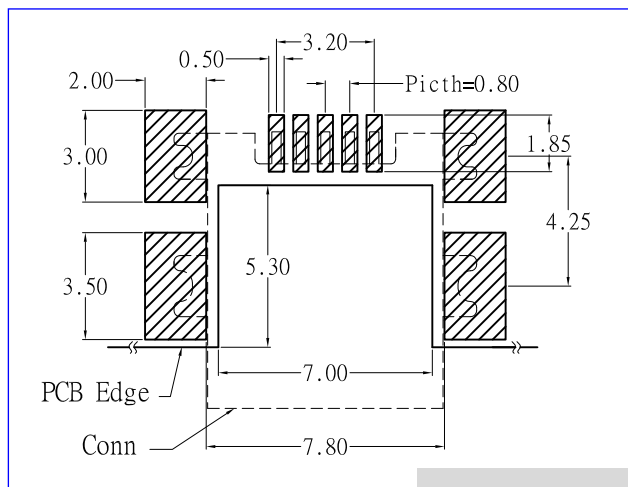

P.C.B LAYOUT

