

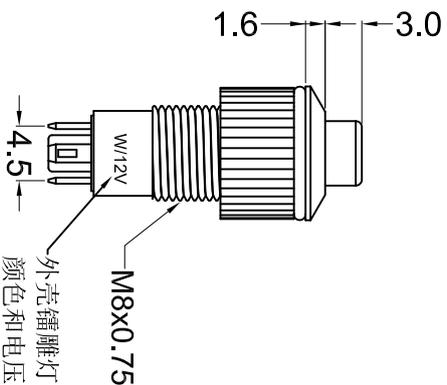


- 备注:
1. 拧螺母, 套垫圈;
  2. 外壳镲雕灯颜色和电压。



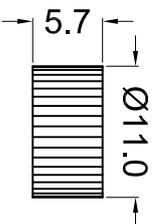


外壳镲雕灯  
颜色和电压

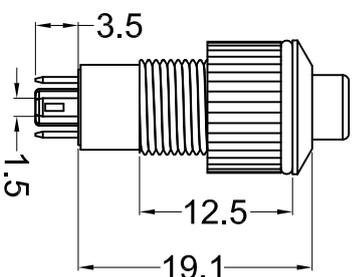

灯脚镀银

开关脚镀金

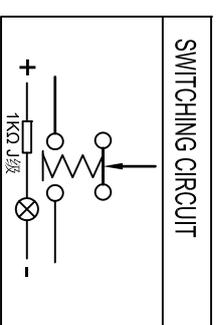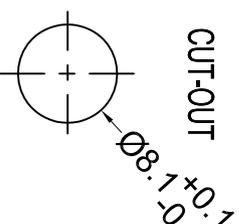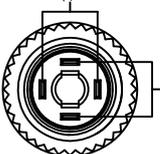

Nut Torque:5~14Nm  
 Operating Pressure:350gf ±80gf  
 Operating Stroke:3.0mm±0.3  
 Protection Grade:IP67 IK08  
 Function:ON-OFF  
 Base:PA66  
 Shell:SUS  
 Button:SUS  
 Rating:0.3A 12V DC/0.2A 24V DC  
 0.1A 36V DC  
 Contact Resistance:50mΩ Max  
 Insulation Resistance:100MΩ Min  
 Dielectric Strength:1000V AC 1 minute  
 Electrical life:50,000 cycles  
 Mechanical life:100,000 cycles  
 Operating Temperature:-20°C~80°C  
 Relative Air Humidity:45%~85%  
 Safety Approval: **RoHS**



公差 TOLERANCES .X±0.5 .XX±0.3 角度 ANGLE ±1° 单位 DIMENSION UNIT mm.

版本 VERSION A0 比例尺 SCALE 1:1 日期 DATE 2022.03.10 品名 TITLE 图号 DRAWING NO 1013279

核准 核对 绘图 审核 日期 DATE ECN NO. APPROVED BY CHECKED BY DRAWN BY

版本 VER 变更说明 CHANGE DESCRIPTION

日期 DATE

ECN NO.

核准

核对

绘图

审核