
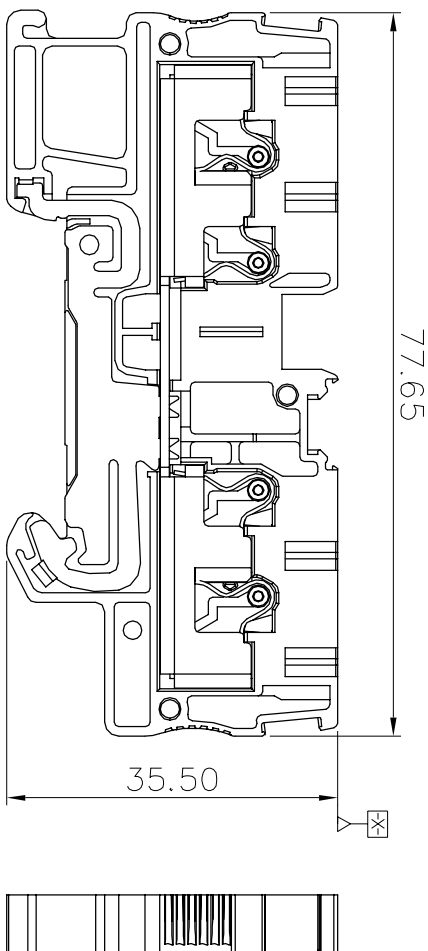


REVISION RECORD			
REV	ECN	DESCRIPTION	DATE

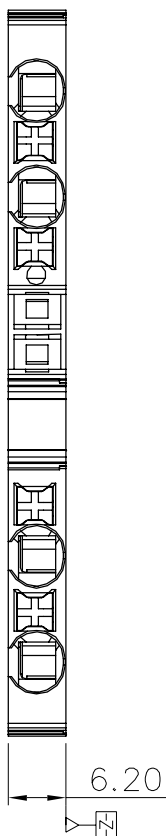

NOTES:

UL/CUL Standard

1. Conductor cross section : 24~10AWG

IEC Standard

1. Conductor cross section :

Wire range(Solid/Stranded)	0.2-4mm ²
Solid	0.2-6mm ²
Stranded	0.2-4mm ²
Stranded with ferrules without plastic sleeve	0.2-4mm ²
Stranded with ferrules with plastic sleeve	0.2-4mm ²

2. Rated Voltage/Current :

Surge voltage category	III
Pollution degree	3
Rated surge voltage(kV)	8

Material:

Insulator	PA66	UL94 V-0
Conductor	Copper alloy	Sn plated
Spring	Stainless steel	
Ground Pin	Copper alloy	Sn plated

General information:

1.Dimension shall be interpreted per

ASME Y14.5-2009

2.Stripping length : 12mm


4. RoHS Compliance

5. Undimensioned Tolerances:

Pitch Range in mm	Nominal Dimension Range in mm				
Over 6	Over 10	Over 30	Over 60	Over 100	0.1/10
To 10	To 20	To 30	To 60	To 100	
Over 6	Over 10	Over 30	Over 60	Over 100	<
To 10	To 20	To 30	To 60	To 100	

Connection method:

1. For Solid wire, peel wire in right length, fix in by rated torque force.
 2. For flexible wire, connect directly after peeling in right length, or furruled on wire and fix in by rated torque force.
- Attention: Torque force should be equable.
No explosive power.

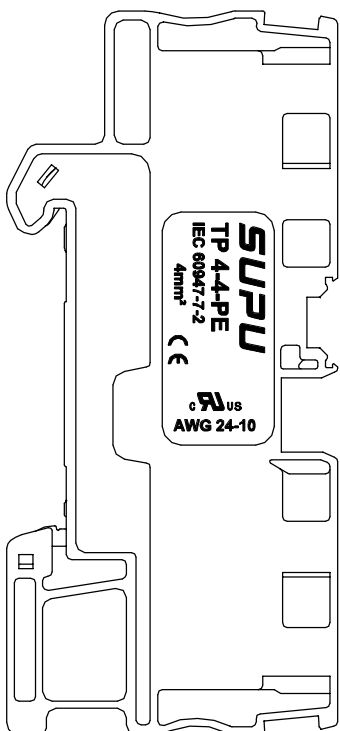

HOW TO ORDER:

TP4-4-PE

Series Color:

No. PE: Yellow and Green

订货号 Order No.	TP4-4-PE		名称 Name	TP系列直插式弹簧 4mm ² 两进两出接地 端子	未注公差 Tolerance	表面 Surface
项目 Item	签字 Signature	日期 Date				
设计 Design	dfz	11/14/19	图号 Drawing No.	PRM001867	版本号 Revision Number	重量 Weight
审核 Check	cw	11/14/19	材料 Material	Notes	M1	比例 Scale
工艺 Process	-	-	物料号 Item No.	412202012	第1页/共1页 1 of 1	 mm
标准化 Unify	-	-				
批准 Approve	lwl	11/14/19	SUPU 宁波盛普电子有限公司 NINGBO SUPU ELECTRONICS CO.,LTD			