
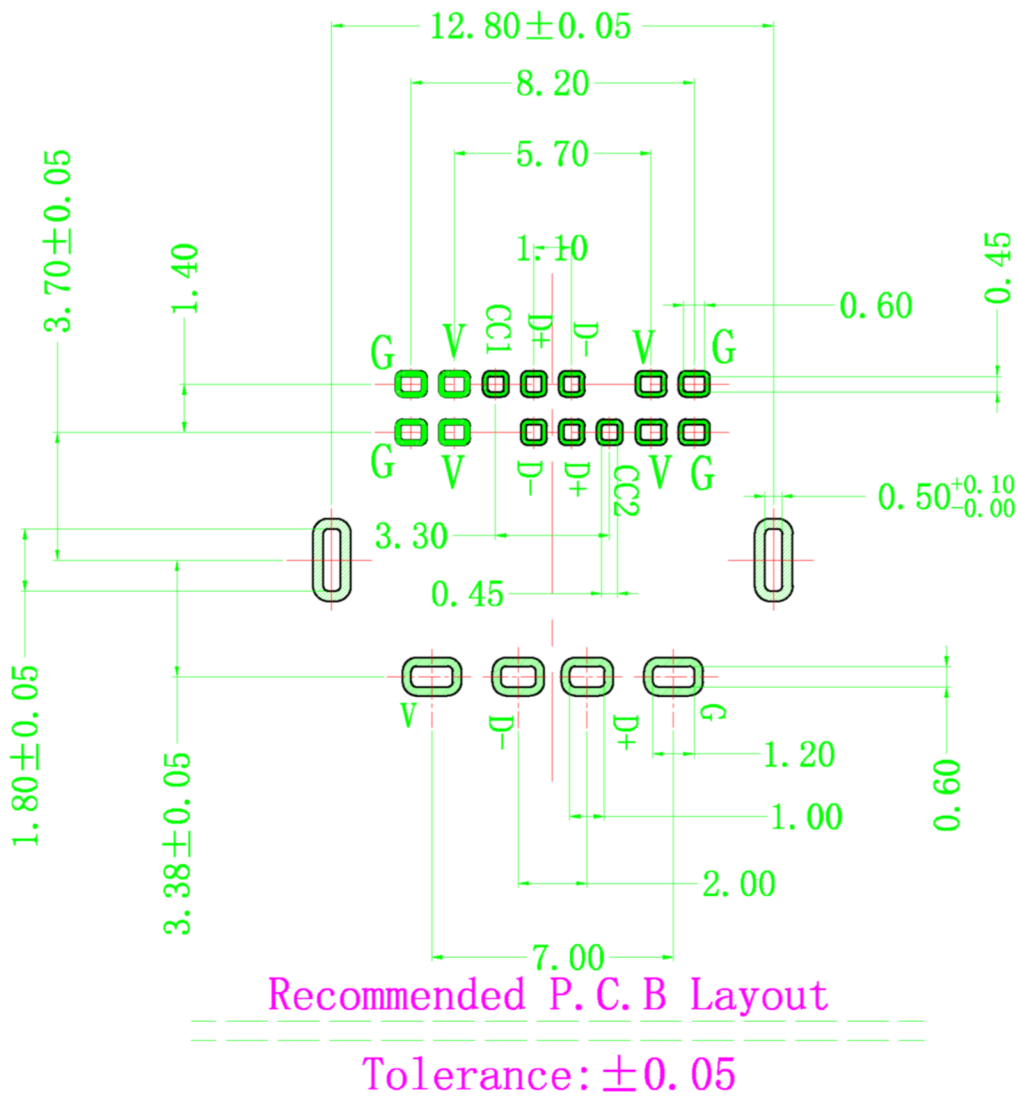
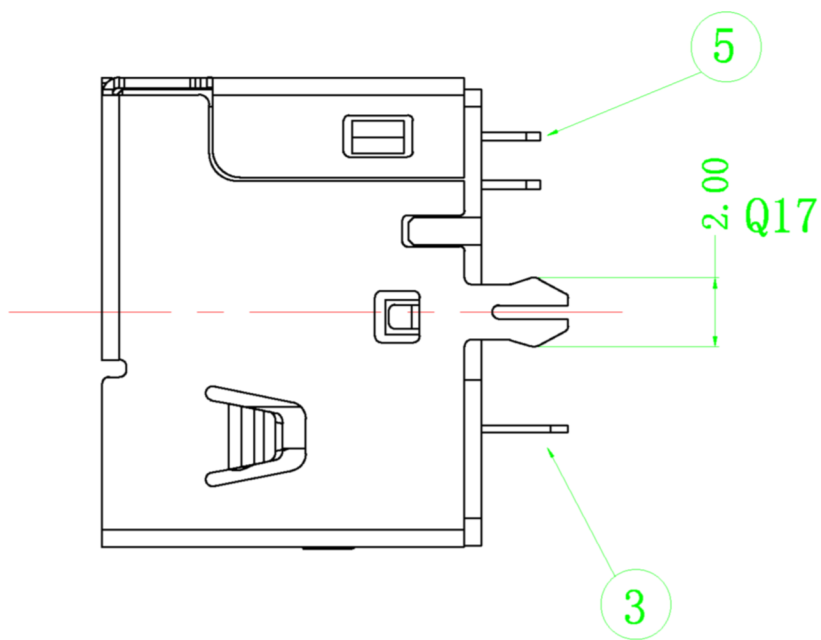
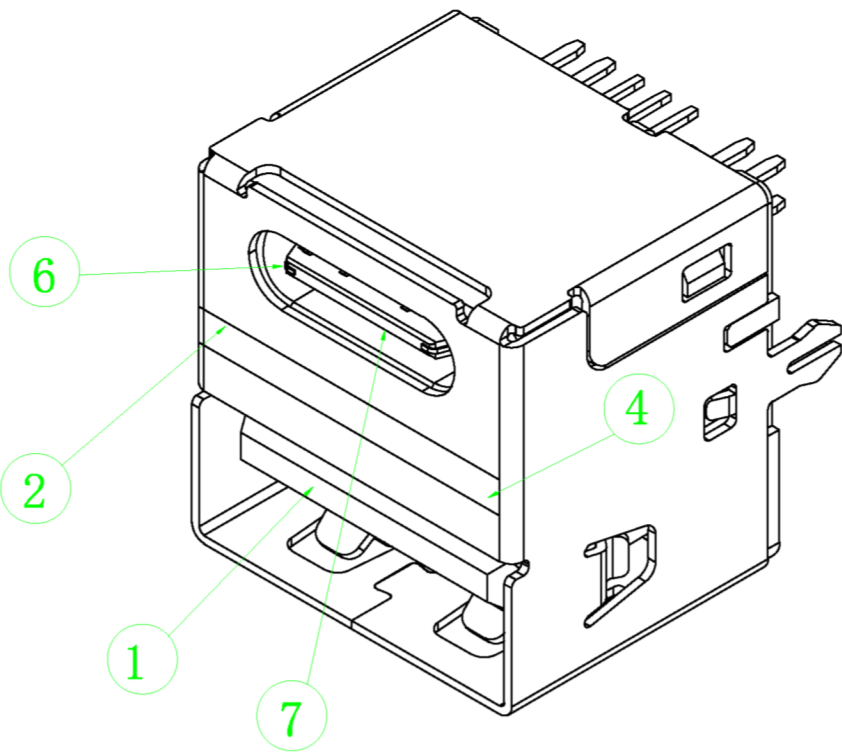
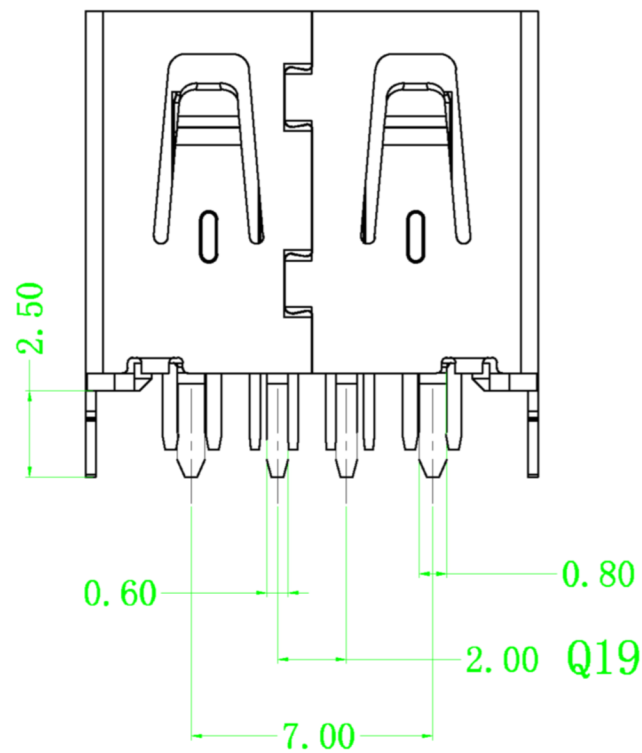
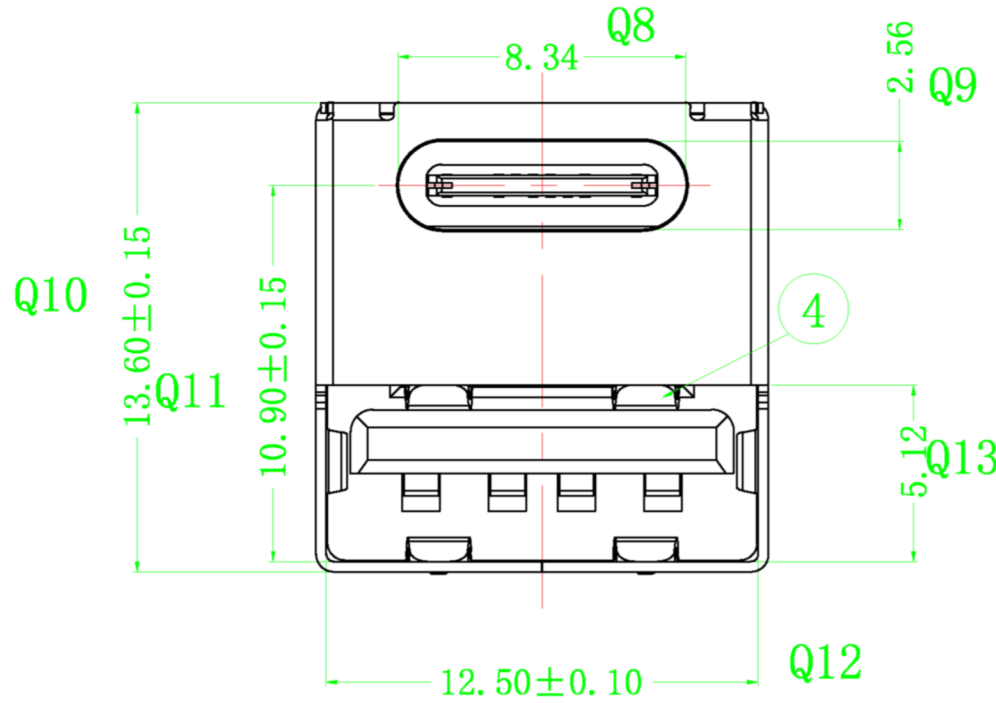
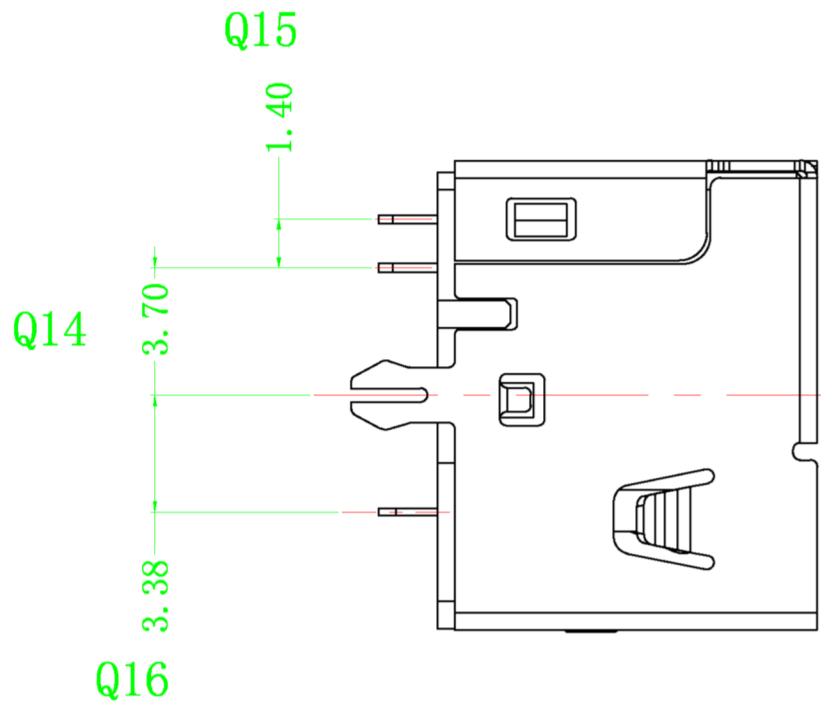


RoHS COMPLIANT

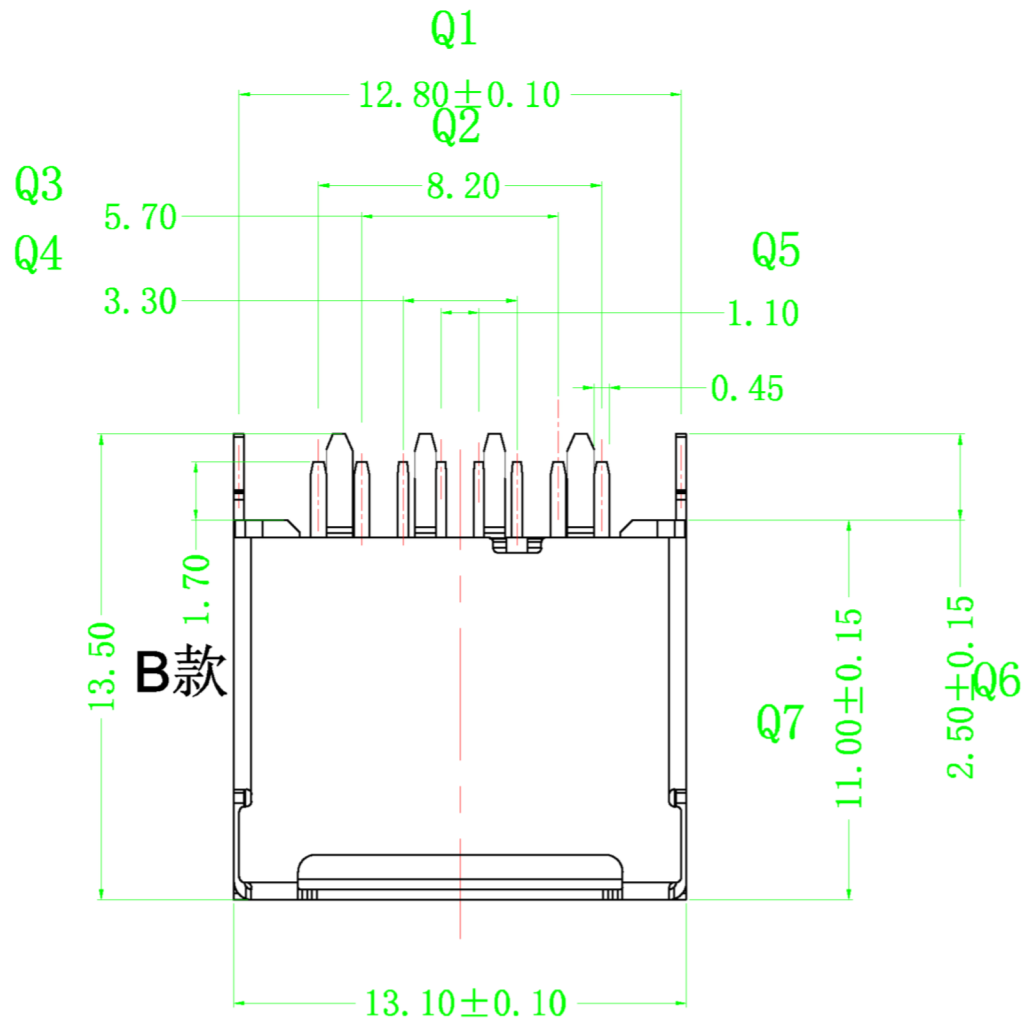

- 备注 (NOTES) :
- 机械性能:
 - 插入力:5~20N.
 - 拔出力:5~20N
 - 耐久寿命:1000 CYCLES.
 - 电气性能:
 - 额定电流:5A MAX .
 - 额定电压:30V MAX.
 - 耐电压:100V AC.
 - 接触阻抗:40mΩ MAX(Initial) , 50mΩ MAX(5千次试验后) .
 - 绝缘阻抗:100MΩ MIN.
 - 环境温度:
 - 温度范围:-30° C ~ +85° C.
 - 盐雾:24H.
 - 尺寸标志:

标有“”为FAI尺寸.

标有“”为重点检验尺寸.

标有“”为 CPK检验尺寸.

UT20FJ014 SX 02ZA

S0:G/F Gold In Contact Area
100u” Tin In Tail Area
S1:1U” Gold In Contact Area
100u” Tin In Tail Area
S3:3u” Gold In Contact Area
100u” Tin In Tail Area
S4:5u” Gold In Contact Area
100u” Tin In Tail Area
S5:15u” Gold In Contact Area
100u” Tin In Tail Area
S6:30u” Gold In Contact Area
100u” Tin In Tail Area

PIN DEFINITION
FRONT VIEW

A12	A11	A10	A9	A8	A7	A6	A5	A4	A3	A2	A1
GND			VBus		D-	D+	CC	VBus			GND
GND			VBus	Vconn				VBus			GND
B1	B2	B3	B4	B5	B6	B7	B8	B9	B10	B11	B12

	A	原版发行			21-03-10		Bai hualin				
ECN(DCN) NO.	版 本	内 容 描 述			日 期	变 更	核 准				

一般公差				材 质	PBT		深圳市金航标电子有限公司				www.kinghelm.com.cn		
DIM	TOL	AMG	TOL	材质规格			KH-TYPE-14P+USB-Z-L				0755-28190160		
.X	±0.5	.X	±0.5	制 图	Bai min	品 名	TYPE C母座14PIN + USB 2.0母单面二合一 180度 铜壳蓝色						
.X	±0.3	.X	±0.3				设 计	Xu bo	料 号	UT20FJ014S002ZA			
.XX	±0.2	.XX	±0.2	审 核	Deng yuanjie	图 号							
.XXX	±0.1	.XXX	±0.1				核 准	Bai hualin	单 位	MM	比 例	1:1	页 次

⑦	TYPE C Moding	LCP+30GF	BLACK	UL 94V-0
⑥	TYPE C中心片	SUS201-H		
⑤	TYPE C端子	C2680-H	——	镀金:G/F Tin 80-120u”Ni:30u”
④	中夹片	SUS201-1/4H	——	
③	USB 端子	C2680-H	——	镀金:G/F Tin 80-120u”Ni:30u”
②	外壳	C2680-H/SPCC	——	Ni :40-60”
①	主体胶芯	LCP+30GF	BLACK	UL 94V-0
序号	描 述	材 质	颜 色	备 注