
 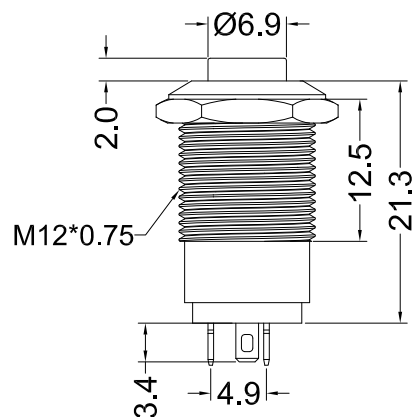

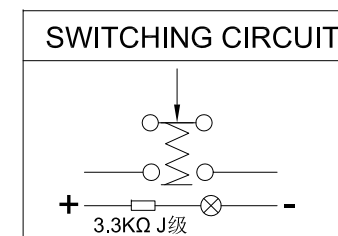


Nut Torque:5~14Nm
 Operating Pressure:300gf $\pm$ 100gf
 Operating Stroke:2.8mm $\pm$ 0.3
 Protection Grade:IP67
 Function:ON-OFF
 Base:PA66
 Shell:Brass,Ni Plating
 Button:SUS
 Lamp Type:LED
 Lamp Life:50000H
 Forward current:20mA Max
 Rating:0.2A 250V AC/0.5A 12V DC
 Contact Resistance:50m Ω Max
 Insulation Resistance:100M Ω Min
 Dielectric Strength:1500VAC 1 minute
 Electrical life:50,000 cycles
 Mechanical life:100,000 cycles
 Operating Temperature:-20°C~80°C
 Relative Air Humidity:45%~85%
 Safety Approval:   

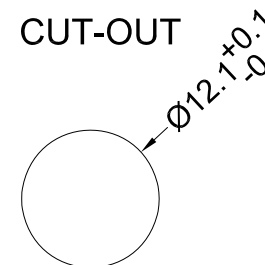

				 D-SWITCH[®] 东莞市德崧电子有限公司 D-SWITCH ELECTRONICS CO.,LTD									
				公差 TOLERANCES		.X± 0.5 .XX± 0.3		角度 ANGLE ±1°		单位	DIMENSION UNIT mm.		
				版本 VERSION	A0	比例尺 SCALE		1:1		日期 DATE	2022.08.03	品 名 TITLE	图 号 DRAWING NO
				核准		核 对			绘图	孙成	PBM-12Z12-HT-G4-R24-B8S-0004	1010719	
版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECN NO.	APPROVED BY		CHECKED BY			DRAWN BY				