

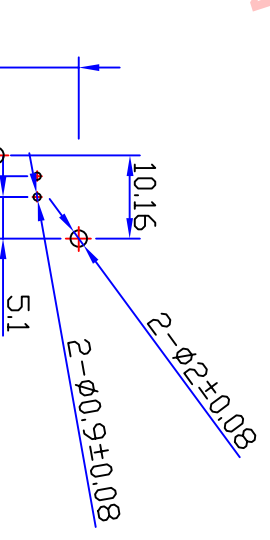
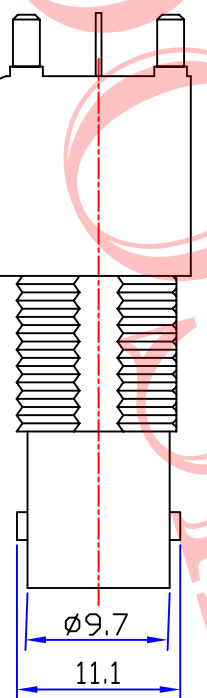
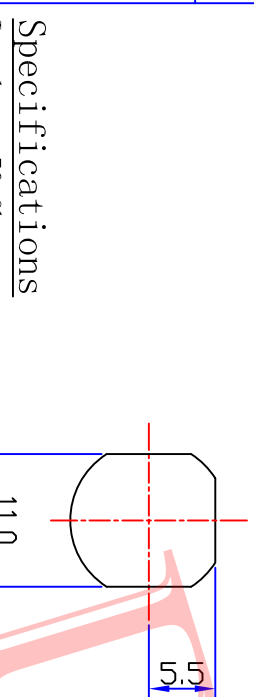


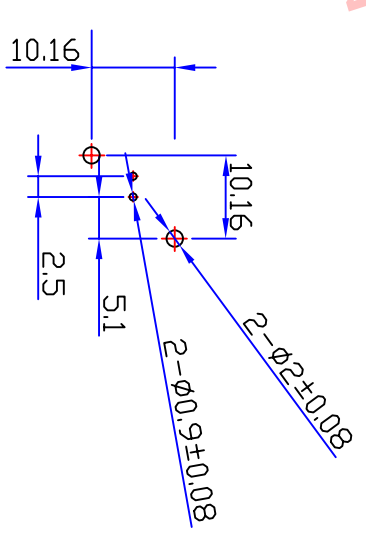

Product NO.		DOSIN-801-0036		
REV	DESCRIPTION	DMN	DATE	APPROVEN
A	First Issue	JIM	2012/11/02	John kime

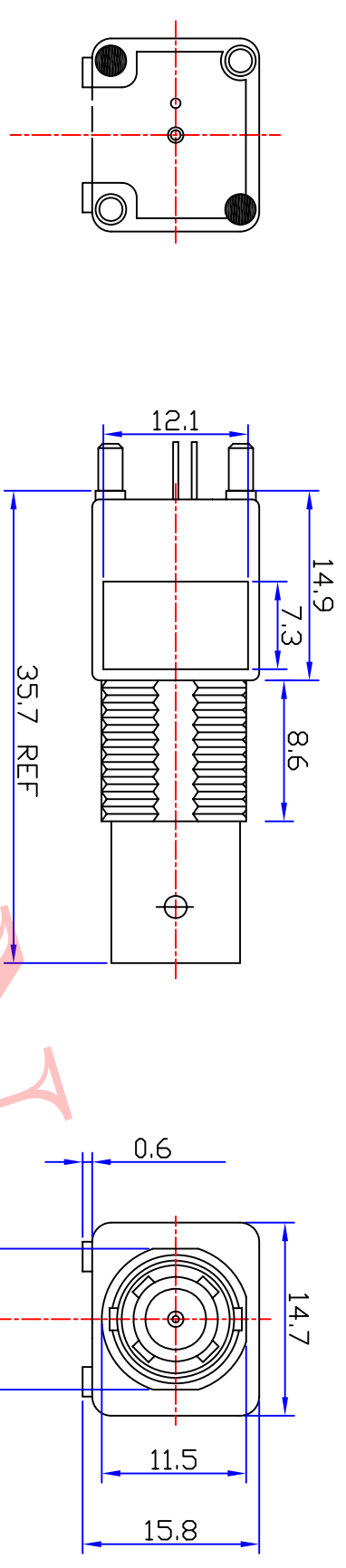

Specifications

Impedance: 50 Ohms  
Frequency Range: DC~3G  
VSWR: 1.3MAX  
Working Voltage: 500V rms @ sea level  
Insulation Resistance: 5000 Ohms min  
Temperature Range: -55°C TO +155°C  
Relative Temperature:  $\leq 95\%$  (40°C  $\pm 2^\circ$  C)  
Drawings products are in line with ROHS standards

NOTE:		Tolerance	
DRAWN	2012/11/10	0-6	$\pm 0.15$
Checked		6-30	$\pm 0.20$
		30-120	$\pm 0.5$
		Angul ar	$\pm 2^\circ$

Name:		BNC CONNECTOR DNN	
SIZE	Product NO.	CAD FILE	REV
A	DOSIN-801-0036	DOSIN-801-0036	B
Date/Time		SHEET:	1 OF 1
2012/11/02			

E		GASKET		TE	NICKEL	1
D		NUT		BRASS	NICKEL	1
C		INSULATOR		POM	NONE	1
B		CONTACT PLATING		BRASS	GOLD	1
A		BODY		ZINC	NICKEL	1
ND		DESCRIPTION		MATERIAL	FINISHED	QTY
A						

APPROVALS

Yalan Xime

19/04/2012

SCALE

1:1

DOSIN Industrial(H.K)Co.Ltd

东莞市德奈五金电子有限公司

Dosin Hardware Electronics Co.,Ltd

E-mail: dosin2005@163.com

dosin2005@dosing.com

dosin2005@dosing.com

http://www.dosing.com

TEL: (0086)769-81153906

FAX: (0086)769-81875836